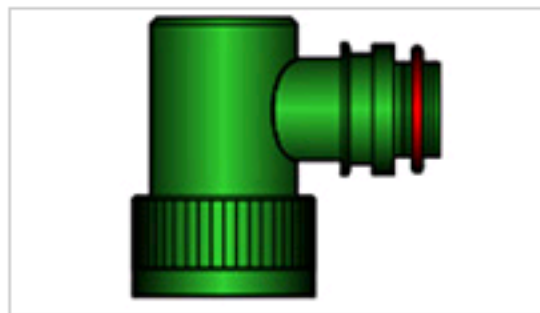


TXR40AZ90-1612AI Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

TXR40AZ90-1612AI
TXR40AZ90-1612AI
 TE Internal Number: EB9482-000

Product Highlights [View All](#)

- Applies To Cable
- Military Style Number = MIL-C-38999
- Style = Tinel Lock
- Connector Code = 40
- 90°

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
 Use the Product Drawing for all design activity

Product Type Features	
Style ?	Tinel Lock
Angle ?	90°
Connector Shell Size	16
Finish	Zinc Nickel
Color	Black (Non Reflective)

Dimensions	
Boot Diameter (mm [in]) ?	26.67 [1.050]
Cable Diameter Range (mm [in])	11.00 - 18.20 [0.430 - 0.720]

Body Features	
Connector Code ?	40
Entry Size	12
Material	Aluminum Alloy

Configuration Features	
Braid ?	Single 36 AWG Braid

Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-C-38999
RoHS/ELV Compliance ?	Not ELV/RoHS compliant
Lead Free Solder Processes ?	Not relevant for lead free process

Conditions for Usage	
Applies To	Cable

Other	
Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Downloaded from [Arrow.com](#)