


OD9238 IP Rated Series



DC Fans - 24, 48V
92mm x 38mm (3.62" x 1.5")

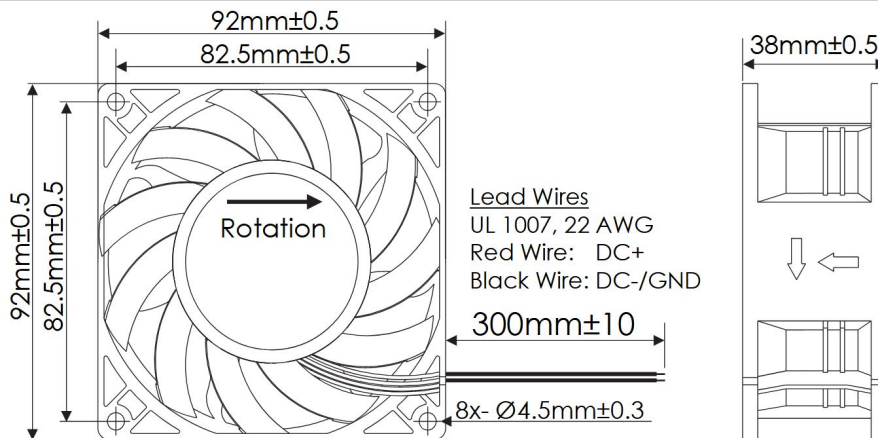

Frame	PBT, UL94 V-0 Plastic	Operating Temperature -20°C ~ +65°C Storage Temperature -20°C ~ +75°C Life Expectancy 60,000 Hours (L10 at 45°C) Installed Options IP Rating, IP68 or IP69K Available Options PWM Speed Control Input Tachometer Output Alarm Output Weight: 0.44 lbs	
Impeller	PBT, UL94 V-0 Plastic		
Connection	2x Lead Wires, 22 AWG		
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected, Electronically Protected, IP68 or IP69K		
Bearing System	Ball Bearings		
Dielectric Strength	500VDC/min, <5mA		
Insulation Resistance	≥10MΩ @ 500V DC		

Part Number	Rated Voltage (Volts DC)	Voltage Range (Volts DC)	Input Power (Watts)	Rated Current (Amps)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OD9238-24HHBIP***	24	15 ~ 26	10.8	0.45	5000	110	58.3	0.86
OD9238-24HBIP***	24	15 ~ 26	9.6	0.40	4500	100	56.2	0.70
OD9238-24MBIP***	24	15 ~ 26	7.2	0.30	4000	89	53.7	0.55
OD9238-24LBIP***	24	15 ~ 26	4.8	0.20	3500	78	50.2	0.42
OD9238-48HHBIP***	48	28 ~ 52	14.4	0.30	5000	110	58.3	0.86
OD9238-48HBIP***	48	28 ~ 52	12.0	0.25	4500	100	56.2	0.70
OD9238-48MBIP***	48	28 ~ 52	9.6	0.20	4000	89	53.7	0.55
OD9238-48LBIP***	48	28 ~ 52	7.2	0.15	3500	78	50.2	0.42

*** Substitute "68" for IP68 Rating, or "69K" for IP69K Rating.