


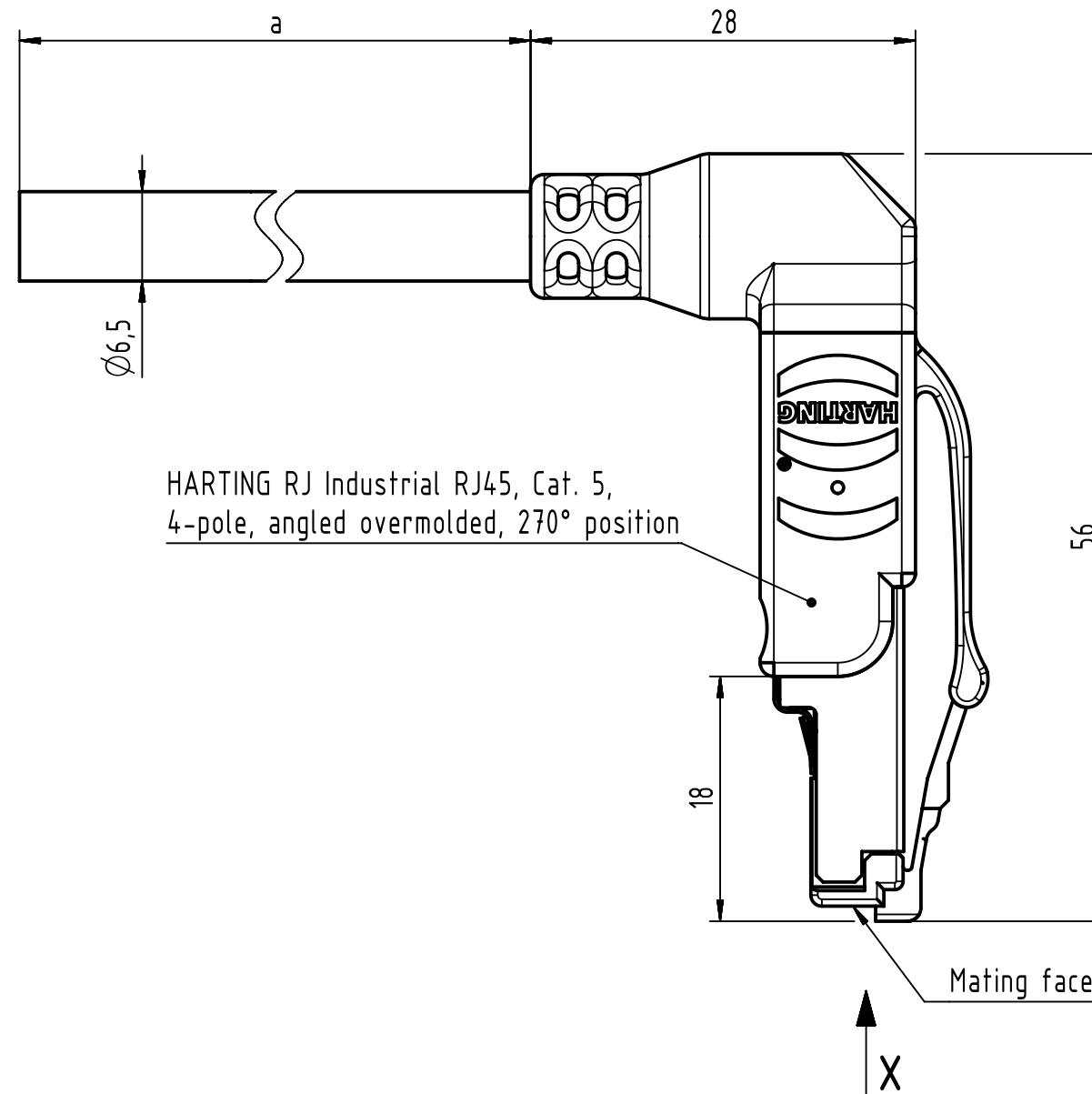


HARTING RJ Industrial RJ45, Cat. 5,
4-pole, angled overmolded, 270° position

Mating face RJ45 acc. to IEC 60603-7

- Protection level: IP20
- Temperature range: -40°C ... +70°C

blue

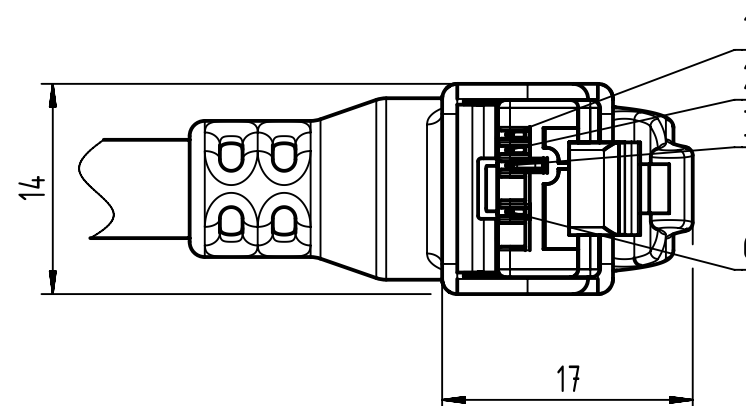

X
male

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved		Created by COSTEA		Inspected by STOCHECIC Stochechi		Standardisation MUNTEANV Muntean	
Department HCS - RO						Date 2019-05-22		State Final Release	
HARTING Customised Solutions D-32339 Espelkamp		Title RJ Industrial Cable Assembly						Doc-Key / ECM-Nr. 100155463/UGD/015/D 500000153138	
		Type TB		Number 09470300XXX				Rev. D	
								Page 1/2	

	1	2	3	4	5	6	7	8	
A									A
	48	09470300048	RJl Ethernet Trailing Cable, 4xAWG 22/7, PUR, Cat. 5+, green	2	91	09470300088	RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC outdoor, Cat. 5+, black	100	
	47	09470300047		1.5	90	09470300087		90	
	46	09470300046		1	89	09470300086		80	
	45	09470300045		0.5	88	09470300085		70	
	44	09470300044		100	87	09470300084		60	
B	43	09470300043	RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC, Cat. 5+, green	90	86	09470300083		50	
	42	09470300042		80	85	09470300082		40	
	41	09470300041		70	84	09470300081		30	
	40	09470300040		60	83	09470300080		20	
	39	09470300039		50	82	09470300079		15	
	38	09470300038		40	81	09470300078		10	B
	37	09470300037		30	80	09470300077		9	
	36	09470300036		20	79	09470300076		8	
	35	09470300035		15	78	09470300075		7	
	34	09470300034		10	77	09470300074		6	
	33	09470300033		9	76	09470300073		5	
	32	09470300032		8	75	09470300072		4	
C	31	09470300031		7	74	09470300071		3	
	30	09470300030		6	73	09470300070		2	
	29	09470300029		5	72	09470300069		1.5	
	28	09470300028		4	71	09470300068		1	C
	27	09470300027		3	70	09470300067		0.5	
	26	09470300026		2	69	09470300066	RJl Ethernet Trailing Cable, 4xAWG 22/7, PUR, Cat. 5+, green	100	
	25	09470300025		1.5	68	09470300065		90	
	24	09470300024		1	67	09470300064		80	
	23	09470300023		0.5	66	09470300091		75	
	22	09470300022	RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green	100	65	09470300063		70	
D	21	09470300021		90	64	09470300062		60	
	20	09470300020		80	63	09470300061		50	
	19	09470300019		70	62	09470300060		40	
	18	09470300018		60	61	09470300090		35	D
	17	09470300017		50	60	09470300059		30	
	16	09470300016		40	59	09470300089		25	
	15	09470300015		30	58	09470300058		20	
	14	09470300014		20	57	09470300057		15	
	13	09470300013		15	56	09470300056		10	
	12	09470300012		10	55	09470300055		9	
E	11	09470300011		9	54	09470300054		8	
	10	09470300010		8	53	09470300053		7	
	9	09470300009		7	52	09470300052		6	
	8	09470300008		6	51	09470300051		5	E
	7	09470300007		5	50	09470300050		4	
	6	09470300006		4	49	09470300049		3	
	5	09470300005		3	Cont. no.	Part no.	Type of cable	Dim. a[m]	
	4	09470300004		2					
	3	09470300003		1.5					
	2	09470300002		1					
F	1	09470300001		0.5					
	Cont. no.	Part no.	Type of cable	Dim. a[m]					
	1								
	2								
	3								
	4								
	5								
	6								
	7								
	8								



All rights reserved
Department HCS - RO

Created by
COSTEA Costea

Inspected by
STOCHECIC Stocheci

Standardisation
MUNTEANV Muntean

Date
2019-05-22

State
Final Release

Title
RJ Industrial Cable Assembly

Doc-Key / ECM-Nr.
100155463/UGD/015/D
500000153138

Type
TB

Number
09470300XXX

Rev.
D

Page
2/2



All Dimensions
in mm

Tech. Character.

Free size tol.

According to production drawing

HARTING Customised Solutions
D-32339 Espelkamp