




Part Number : [2158600011](#)

Product Description : PowerPlane OCP ORV3 Power Shelf Cable Assembly with 3 Mounting Screws, 450.00mm Cable Length

Series Number : 215860

Status : Active

Product Category : Power and Signal Cable Assemblies

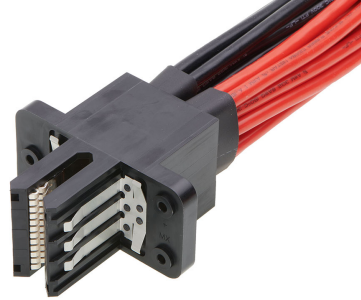

Documents & Resources

Drawings

[Drawing 2158600011_sd.pdf](#)

Specifications

[Product Specification 2158470001-PS-000.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Power and Signal Cable Assemblies
Series	215860
Description	PowerPlane OCP ORV3 Power Shelf Cable Assembly with 3 Mounting Screws, 450.00mm Cable Length
Application	Busbar-to-Cable, Power
Assembly Configuration	Single Ended Connector
Connector to Connector	PowerPlane-to-Pigtail
Product Family	PowerPlane Busbar Power Connectors
Product Name	PowerPlane
Type	Discrete Wire Assembly, High-Power Assembly
UPC	196823091643

Agency

CSA	LR19980
UL	E29179

Electrical

Current - Maximum per Contact	500.0A+
Voltage - Maximum	52V

Physical

Cable Length	450.00mm
Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-0
Gender	Female-Pigtail
Material - Metal	Copper Alloy
Material - Plating Mating	Silver
Material - Resin	Nylon

Overmolded	No
Packaging Type	Bag
Single Ended	Yes
Termination Interface Style	Welded
Wire/Cable Type	UL 3132
Wire Size (AWG)	8

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mates With	OCP ORV3 Busbar

This document was generated on Sep 22, 2024