

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0510480600

Status:

Active

Description:

2.00mm Pitch Cable Holder, Vertical, Low Profile, for Ribbon Cable, 6 Circuits

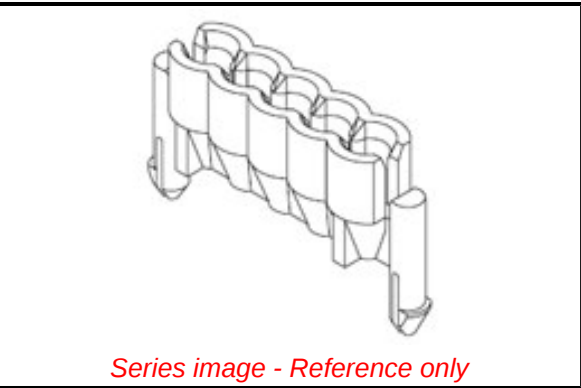

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

General

Product Family

Ribbon Cable / Wire Trap Connectors

Series

51048

Component Type

One Piece

Glow-Wire Compliant

No

Product Name

Board-In, Cable Holder

UPC

800753574731

Physical

Circuits (Loaded)

6

Color - Resin

Natural

Entry Angle

Vertical

Lock to Mating Part

None

Material - Plating Mating

N/A

Material - Resin

Nylon

Net Weight

139.300/mg

Number of Rows

1

PCB Retention

Yes

PCB Thickness - Recommended

1.60mm

Packaging Type

Bag

Pitch - Mating Interface

2.00mm

Pitch - Termination Interface

2.00mm

Polarized to Mating Part

N/A

Polarized to PCB

No

Stackable

No

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-40°C to +105°C

Wire Insulation Diameter

1.60mm max.

Wire Size AWG

26

Wire/Cable Type

Ribbon Cable

Electrical

Current - Maximum per Contact

N/A

Voltage - Maximum

N/A

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-51048-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/01/2017 (12

January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51048 Series

Mates With

N/A

Use With

Topcoated Ribbon Cable

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION