

Receptacles

Features:

- DIN Rail, Panel Mount or Wall Mount
- Rating: 15A/125V AC
- Finger Protection: IP54
- Available in 3 colors.

PANEL MOUNT



WALL MOUNT



DIN RAIL MOUNT



External Dimension (HxWxL mm)

36.5 x 61.5 x 50

Stripping Length

10 mm

Insulation Material

Thermoplastic

Type of Connection

3 screw clamps

Approvals*

c  us
E154664

Voltage Rating

125 V

Current Rating

15 A

50 x 71 x 53.5

10 mm

Thermoplastic

3 screw clamps

c  us
E154664

125 V

15 A

58.5 x 84 x 53.5

10 mm

Thermoplastic

3 screw clamps

c  us
E154664

125 V

15 A

Cat. No.

Std. Pk.

Cat. No.

Std. Pk.

Cat. No.

Std. Pk.

Complete Kit:

Blue
Gray
Black

PMRBU 1
PMRGR 1
PMRBA 1

WMRBU* 1
WMRGR* 1
WMRBA 1







DMRBU* 1
DMRGR* 1
DMRBA 1

Optional Accessory
Sealing Gasket
for Panel Mount Receptacles

SEALGASK 1

Includes Sealing Gasket

Includes Sealing Gasket

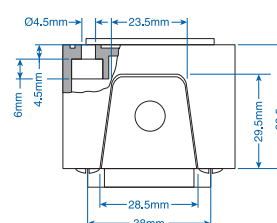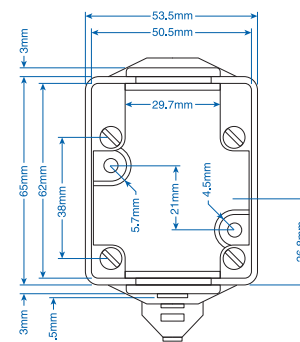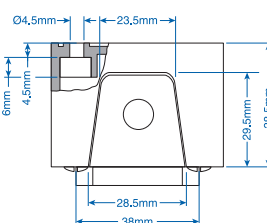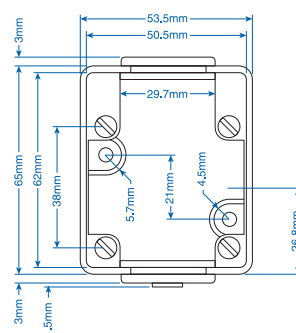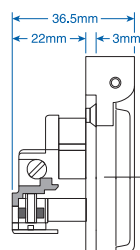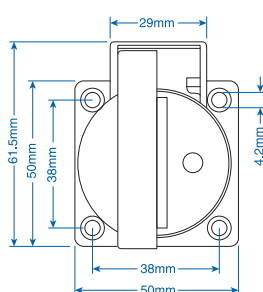

* Please Note:


Matching colored blue and gray assembly enclosures have been discontinued and are available while our stock supplies last.

Please check with customer service for availability.


The front socket and hinged protective cover are still available in blue and gray.

UL approval applies to outlet only, not enclosure or DIN rail clip.


PANEL MOUNT

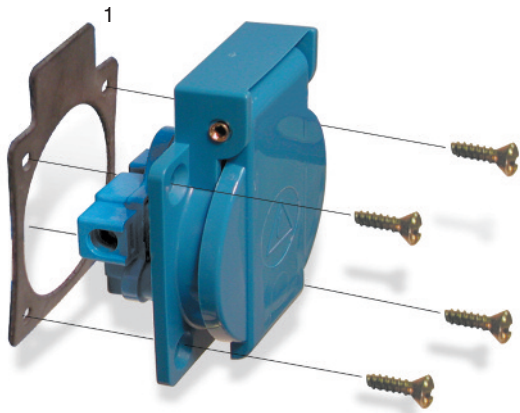


Wiring of Receptacles

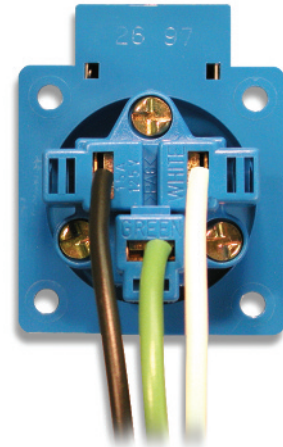

WALL MOUNT

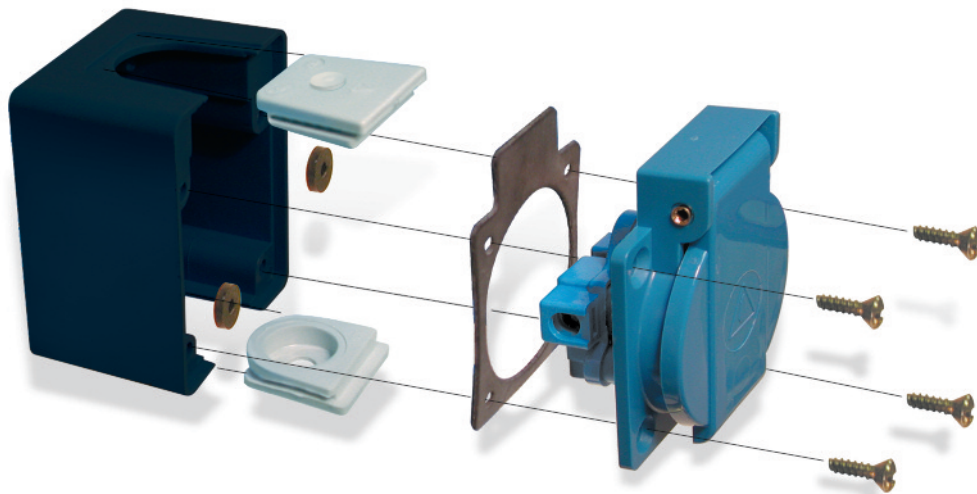

DIN RAIL MOUNT

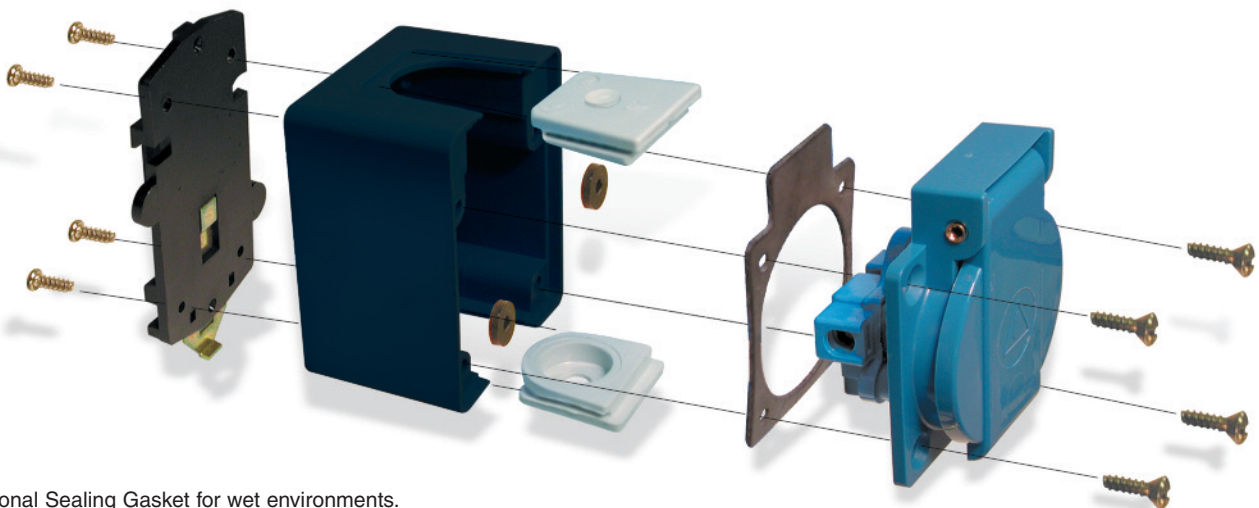

¹ Optional Sealing Gasket for wet environments.