


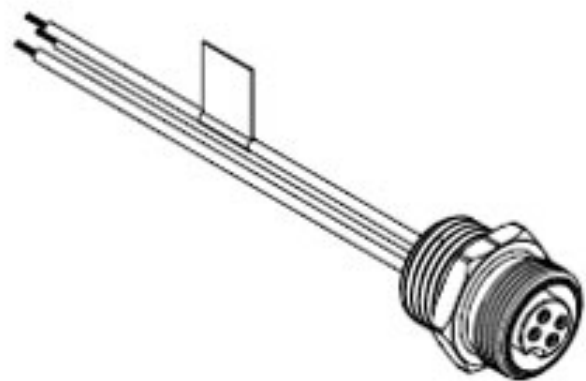

Part Number : [1300130393](#)
Product Description : Mini-Change A-Size
Receptacle, 4 Poles, PG 13.5 Threads, Female
(Straight) to 18 AWG Leads, 2.0m (6.56')
Length
Series Number : 130013
Status : Active
Product Category : Circular Industrial
Connectors
Engineering Number : 1R4D04A16M020



Documents & Resources

Drawings
[1300130393_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Not Reviewed per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	130013
Description	Mini-Change A-Size Receptacle, 4 Poles, PG 13.5 Threads, Female (Straight) to 18 AWG Leads, 2.0m (6.56') Length
IP Rating	IP67
NEMA Rating	NEMA 6
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78678846007

Agency

CSA	LR6837
-----	--------

Electrical

Current - Maximum per Contact	5.6A
Voltage - Maximum	300V AC/DC

Physical

Coupling Type	External Thread
Gender	Female
Keyway	Single
Length	2.0m
Material - Component	PVC
Mounting Thread Size	PG13.5
Net Weight	1.000/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20° to +105°C

Wire/Cable Type	UL 1061
Wire Size (AWG)	18

This document was generated on Apr 26, 2025