




COM-KNOBS

Modern collet knob system

Aesthetic design, a modern selection of pastel colors, and a secure collet fixing system are the main features of our COM-KNOBS range. These very attractive tuning knobs will give your application a high-quality appearance.

- modern and innovative control knobs
- cover with a matt chrome finish for a classy metallic look (sizes 23-40)
- reliable operation with the tried and tested collet fixing system
- convenient assembly from the front with tight fitting on the axis
- with/without slot for arrow marking elements
- clip-on covers with or without a finger recess for finer control and adjustment (sizes 40-50)
- also suitable for fitting accessory disks, dials, stator and nut covers
- the design is similar to our innovative TOP-KNOBS series; this guarantees you a uniform appearance when using the two knob technologies
- modern color combinations

knob sizes	boreholes
ø 16, 20, 23 mm	4 mm, 6 mm, 1/4"
ø 31 mm	6 mm, 1/4"
ø 40, 50 mm	6 mm, 8 mm

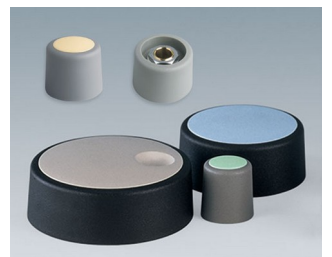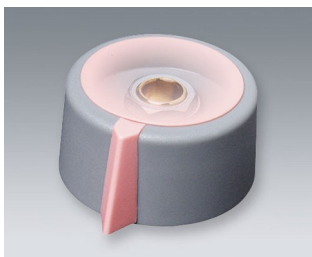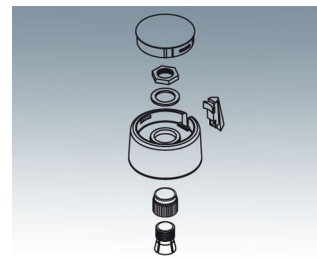

COM-KNOBS

Applications and Examples

For rotary potentiometers with shaft ends corresponding to DIN 41591.

- Measuring and control technology
- Medical and wellness devices
- Laboratory equipment
- Heating and air conditioning
- Communication equipment
- Building management



Controller for LED lighting in image processing and microscopy



Operating element for a universal centrifuge



Operating element for an intensive care ventilator



Operating elements for children's kitchen furniture



Operating elements for Klangfinder



Operating elements for ultrasonic nebulizer



USB SDR VFO Tuning knob

View Customizing Options

What do you still need for your own very personal product? We can supply enclosures and tuning knobs with all necessary modifications for fitting your electronic components. Customizing options for Com-Knobs



Machining



Lacquering



Printing



Laser marking




Installation / Assembly of accessories

COM-KNOBS


Select Versions




A3016048
COM-KNOBS 16, with recess
PA 6
volcano
16x16mm 4mm

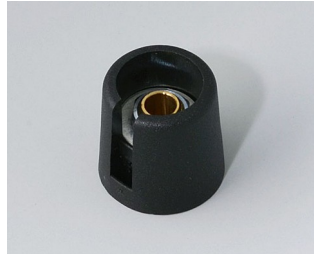

A3016049
COM-KNOBS 16, with recess
PA 6
nero
16x16mm 4mm

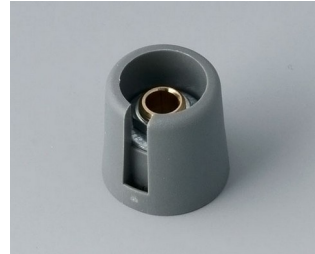

A3016068
COM-KNOBS 16, with recess
PA 6
volcano
16x16mm 6mm

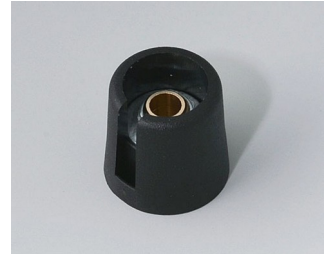

A3016069
COM-KNOBS 16, with recess
PA 6
nero
16x16mm 6mm



A3016638
COM-KNOBS 16, with recess
PA 6
volcano
16x16mm 1/4"



A3016639
COM-KNOBS 16, with recess
PA 6
nero
16x16mm 1/4"



A3020048
COM-KNOBS 20, with recess
PA 6
volcano
20x16mm 4mm



A3020049
COM-KNOBS 20, with recess
PA 6
nero
20x16mm 4mm



A3020068
COM-KNOBS 20, with recess
PA 6
volcano
20x16mm 6mm



A3020069
COM-KNOBS 20, with recess
PA 6
nero
20x16mm 6mm



A3020638
COM-KNOBS 20, with recess
PA 6
volcano
20x16mm 1/4"



A3020639
COM-KNOBS 20, with recess
PA 6
nero
20x16mm 1/4"



A3023048
COM-KNOBS 23, with recess
PA 6
volcano
23x16mm 4mm



A3023049
COM-KNOBS 23, with recess
PA 6
nero
23x16mm 4mm



A3023068
COM-KNOBS 23, with recess
PA 6
volcano
23x16mm 6mm



A3023069
COM-KNOBS 23, with recess
PA 6
nero
23x16mm 6mm


COM-KNOBS



A3023638
COM-KNOBS 23, with recess
PA 6
volcano
23x16mm 1/4"



A3023639
COM-KNOBS 23, with recess
PA 6
nero
23x16mm 1/4"

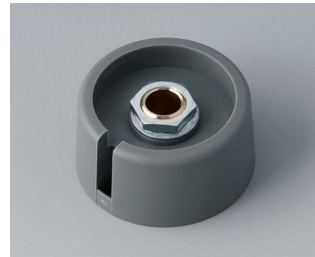

A3031068
COM-KNOBS 31, with recess
PA 6
volcano
31x16mm 6mm



A3031069
COM-KNOBS 31, with recess
PA 6
nero
31x16mm 6mm



A3031638
COM-KNOBS 31, with recess
PA 6
volcano
31x16mm 1/4"



A3031639
COM-KNOBS 31, with recess
PA 6
nero
31x16mm 1/4"



A3040068
COM-KNOBS 40, with recess
PA 6
volcano
40x16mm 6mm



A3040069
COM-KNOBS 40, with recess
PA 6
nero
40x16mm 6mm



A3040088
COM-KNOBS 40, with recess
PA 6
volcano
40x16mm 8mm



A3040089
COM-KNOBS 40, with recess
PA 6
nero
40x16mm 8mm




A3050068
COM-KNOBS 50, with recess
PA 6
volcano
50x16mm 6mm



A3050069
COM-KNOBS 50, with recess
PA 6
nero
50x16mm 6mm



A3050088
COM-KNOBS 50, with recess
PA 6
volcano
50x16mm 8mm

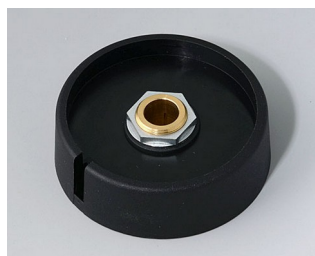

A3050089
COM-KNOBS 50, with recess
PA 6
nero
50x16mm 8mm



A3116048
COM-KNOBS 16, without recess
PA 6
volcano
16x16mm 4mm




A3116049
COM-KNOBS 16, without recess
PA 6
nero
16x16mm 4mm


COM-KNOBS



A3116068
COM-KNOBS 16, without recess
PA 6
volcano
16x16mm 6mm

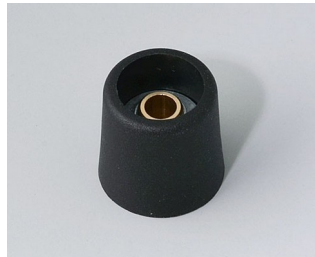

A3116069
COM-KNOBS 16, without recess
PA 6
nero
16x16mm 6mm

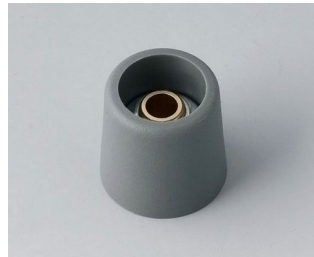

A3116638
COM-KNOBS 16, without recess
PA 6
volcano
16x16mm 1/4"



A3116639
COM-KNOBS 16, without recess
PA 6
nero
16x16mm 1/4"



A3120048
COM-KNOBS 20, without recess
PA 6
volcano
20x16mm 4mm



A3120049
COM-KNOBS 20, without recess
PA 6
nero
20x16mm 4mm



A3120068
COM-KNOBS 20, without recess
PA 6
volcano
20x16mm 6mm



A3120069
COM-KNOBS 20, without recess
PA 6
nero
20x16mm 6mm



A3120638
COM-KNOBS 20, without recess
PA 6
volcano
20x16mm 1/4"



A3120639
COM-KNOBS 20, without recess
PA 6
nero
20x16mm 1/4"



A3123048
COM-KNOBS 23, without recess
PA 6
volcano
23x16mm 4mm



A3123049
COM-KNOBS 23, without recess
PA 6
nero
23x16mm 4mm



A3123068
COM-KNOBS 23, without recess
PA 6
volcano
23x16mm 6mm



A3123069
COM-KNOBS 23, without recess
PA 6
nero
23x16mm 6mm



A3123638
COM-KNOBS 23, without recess
PA 6
volcano
23x16mm 1/4"



A3123639
COM-KNOBS 23, without recess
PA 6
nero
23x16mm 1/4"

COM-KNOBS



A3131068
COM-KNOBS 31, without recess
PA 6
volcano
31x16mm 6mm



A3131069
COM-KNOBS 31, without recess
PA 6
nero
31x16mm 6mm




A3131638
COM-KNOBS 31, without recess
PA 6
volcano
31x16mm 1/4"



A3131639
COM-KNOBS 31, without recess
PA 6
nero
31x16mm 1/4"



A3140068
COM-KNOBS 40, without recess
PA 6
volcano
40x16mm 6mm

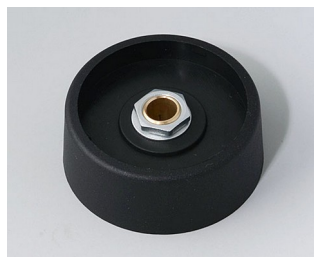

A3140069
COM-KNOBS 40, without recess
PA 6
nero
40x16mm 6mm



A3140088
COM-KNOBS 40, without recess
PA 6
volcano
40x16mm 8mm



A3140089
COM-KNOBS 40, without recess
PA 6
nero
40x16mm 8mm




A3150068
COM-KNOBS 50, without recess
PA 6
volcano
50x16mm 6mm



A3150069
COM-KNOBS 50, without recess
PA 6
nero
50x16mm 6mm



A3150088
COM-KNOBS 50, without recess
PA 6
volcano
50x16mm 8mm

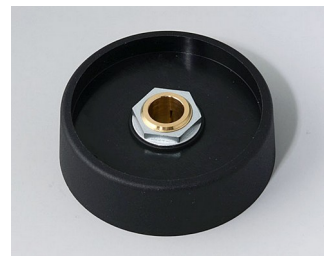

A3150089
COM-KNOBS 50, without recess
PA 6
nero
50x16mm 8mm

System components to complete



A3216003
Cover 16
PA 6
coral



A3216004
Cover 16
PA 6
beach



A3216005
Cover 16
PA 6
lagoon



A3216006
Cover 16
PA 6
sky

COM-KNOBS



A3216007
Cover 16
PA 6
mineral



A3216009
Cover 16
PA 6
nero



A3220003
Cover 20
PA 6
coral



A3220004
Cover 20
PA 6
beach



A3220005
Cover 20
PA 6
lagoon



A3220006
Cover 20
PA 6
sky



A3220007
Cover 20
PA 6
mineral



A3220009
Cover 20
PA 6
nero



A3223003
Cover 23
PA 6
coral



A3223004
Cover 23
PA 6
beach



A3223005
Cover 23
PA 6
lagoon



A3223006
Cover 23
PA 6
sky



A3223007
Cover 23
PA 6
mineral



A3223009
Cover 23
PA 6
nero



A3223011
Cover 23
ABS (UL 94 HB)
matt chromed



A3231003
Cover 31
PA 6
coral

COM-KNOBS



A3231004
Cover 31
PA 6
beach



A3231005
Cover 31
PA 6
lagoon



A3231006
Cover 31
PA 6
sky



A3231007
Cover 31
PA 6
mineral



A3231009
Cover 31
PA 6
nero



A3231011
Cover 31
ABS (UL 94 HB)
matt chromed



A3240003
Cover 40
PA 6
coral



A3240004
Cover 40
PA 6
beach



A3240005
Cover 40
PA 6
lagoon



A3240006
Cover 40
PA 6
sky



A3240007
Cover 40
PA 6
mineral



A3240009
Cover 40
PA 6
nero



A3240011
Cover 40
ABS (UL 94 HB)
matt chromed



A3240103
Cover 40, with finger grip
PA 6
coral



A3240104
Cover 40, with finger grip
PA 6
beach



A3240105
Cover 40, with finger grip
PA 6
lagoon

COM-KNOBS



A3240106
Cover 40, with finger grip
PA 6
sky



A3240107
Cover 40, with finger grip
PA 6
mineral



A3240109
Cover 40, with finger grip
PA 6
nero



A3240111
Cover 40, with finger grip
ABS (UL 94 HB)
matt chromed



A3250003
Cover 50
PA 6
coral



A3250004
Cover 50
PA 6
beach



A3250005
Cover 50
PA 6
lagoon



A3250006
Cover 50
PA 6
sky



A3250007
Cover 50
PA 6
mineral



A3250009
Cover 50
PA 6
nero



A3250103
Cover 50, with finger grip
PA 6
coral



A3250104
Cover 50, with finger grip
PA 6
beach



A3250105
Cover 50, with finger grip
PA 6
lagoon



A3250106
Cover 50, with finger grip
PA 6
sky



A3250107
Cover 50, with finger grip
PA 6
mineral



A3250109
Cover 50, with finger grip
PA 6
nero

COM-KNOBS



A3316003
Peak 16
PA 6
coral



A3316004
Peak 16
PA 6
beach



A3316005
Peak 16
PA 6
lagoon



A3316006
Peak 16
PA 6
sky



A3316007
Peak 16
PA 6
mineral



A3316009
Peak 16
PA 6
nero



A3320003
Peak 20 - 50
PA 6
coral



A3320004
Peak 20 - 50
PA 6
beach



A3320005
Peak 20 - 50
PA 6
lagoon



A3320006
Peak 20 - 50
PA 6
sky



A3320007
Peak 20 - 50
PA 6
mineral



A3320009
Peak 20 - 50
PA 6
nero

Accessory "screws"



A6207009
Round nut M7 x 0.75



A6210009
Round nut M10 x 0.75



A6295009
Round nut 3/8"-32G



A6300000
Spanner

COM-KNOBS



A7516000
Nut cover 16, without line
ABS (UL 94 HB)
black RAL 9005



A7516010
Nut cover 16, with line
ABS (UL 94 HB)
black RAL 9005



A7516018
Nut cover 16, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A7616000
Nut cover 16, without line
ABS (UL 94 HB)
black RAL 9005




A7616008
Nut cover 16, without line
ABS (UL 94 HB)
dusty gray RAL 7037


Accessory




A4416001
Dial 16
PC (UL 94 HB)
transparent

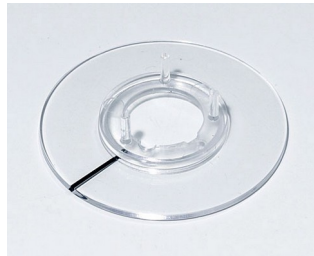

A4416010
Dial 16
PC (UL 94 HB)
transparent

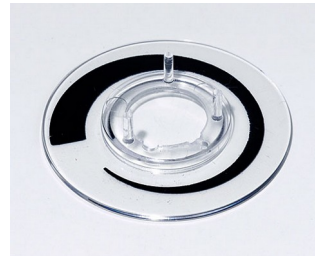


A4416020
Dial 16
PC (UL 94 HB)
transparent

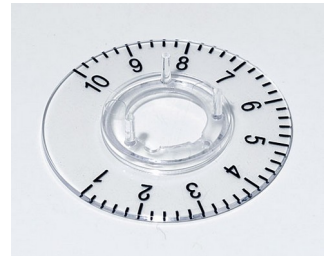


A4416060
Dial 16
PC (UL 94 HB)
transparent



A4420001
Dial 20
PC (UL 94 HB)
transparent

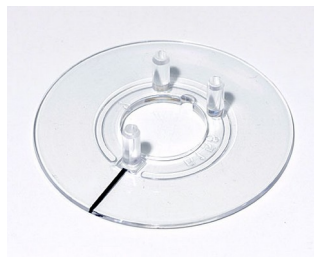

A4420010
Dial 20
PC (UL 94 HB)
transparent

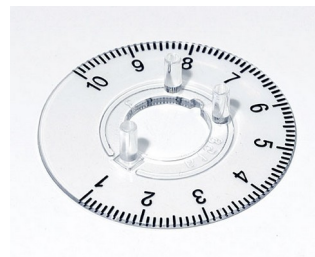


A4420060
Dial 20
PC (UL 94 HB)
transparent




A4423020
Dial 23
PC (UL 94 HB)
transparent

COM-KNOBS

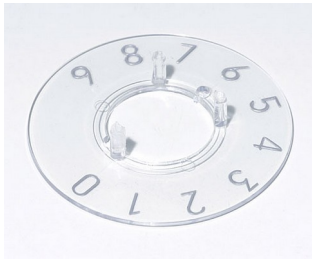


A4423039
Dial 23
PC (UL 94 HB)
transparent

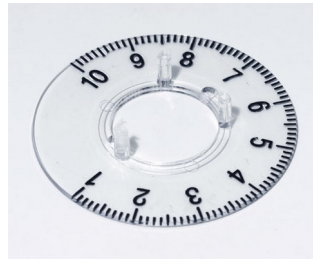

A4423060
Dial 23
PC (UL 94 HB)
transparent



A4431010
Dial 31
PC (UL 94 HB)
transparent

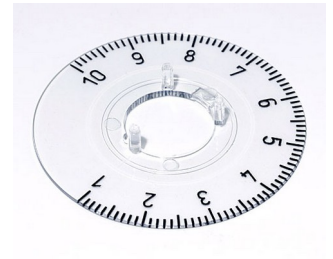

A4431060
Dial 31
PC (UL 94 HB)
transparent



A6016019
Stator 16
Aluminum



A6020019
Stator 20
Aluminum



A6023019
Stator 23
Aluminum




A7316000
Disk 16, without line
ABS (UL 94 HB)
black RAL 9005



A7316010
Disk 16, with line
ABS (UL 94 HB)
black RAL 9005



A7323010
Disk 23, with line
ABS (UL 94 HB)
black RAL 9005

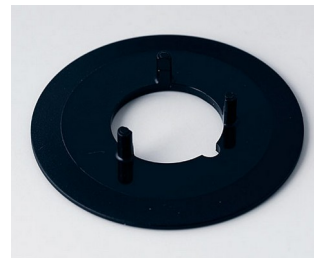

A7331000
Disk 31, without line
ABS (UL 94 HB)
black RAL 9005



A7331010
Disk 31, with line
ABS (UL 94 HB)
black RAL 9005



A7340010
Disk 40, with line
ABS (UL 94 HB)
black RAL 9005

Subject to technical modification without notice. © by OKW Gehäusesysteme, Buchen/Germany.