

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0260010603

Status:


Active

Overview:

Ribbon Cable Jumpers

Description:

2.54mm Pitch Board-to-Board Ribbon Cable Jumper - 24 AWG, Solid Tinned, 6 Circuits, Kinked Tails, 0.076m Length

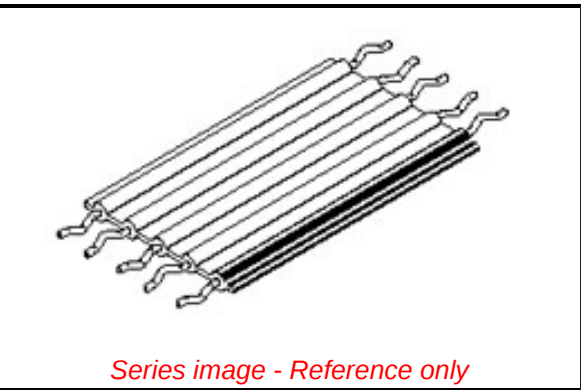

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	26001
Crimp Quality Equipment	Yes
Geographic Area	Asia
Overview	Ribbon Cable Jumpers
Product Name	Ribbon
UPC	800753884809
Physical	
Cable Length	0.076m
Circuits (Loaded)	6
Circuits (maximum)	6
Insulation	PVC
Packaging Type	Bag
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	24
Wire/Cable Type	(1x24) Solid, Tinned
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-26001-001

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

26001 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION