
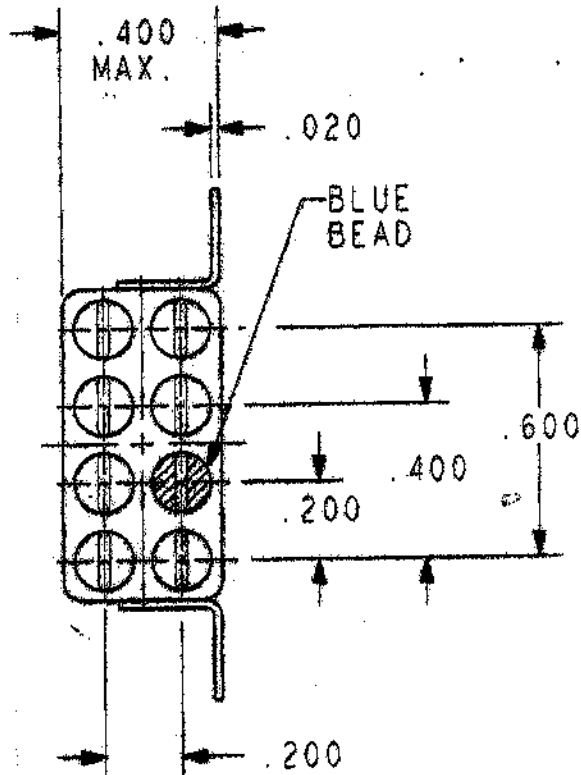


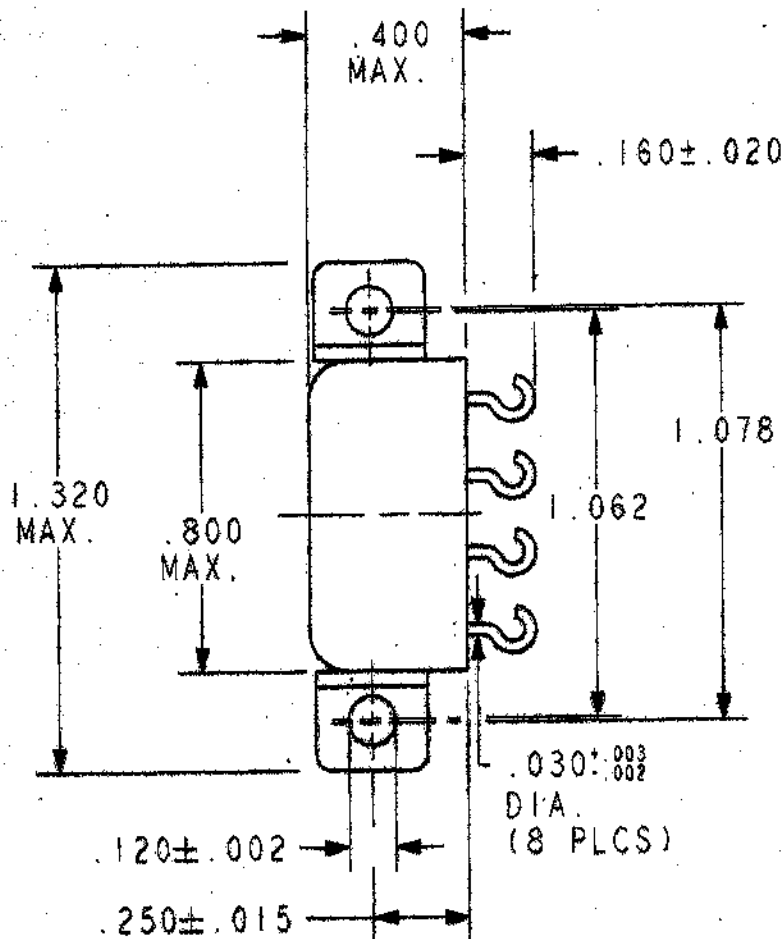

REV. 0


DCO 17298

COIL: @ 25°C
 RESISTANCE 700 OHMS ±10%
 NOMINAL VOLTAGE 22.0 VDC
 MUST OPERATE 8.36 VDC
 MUST RELEASE 5.0 VDC MAX., 0.63 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

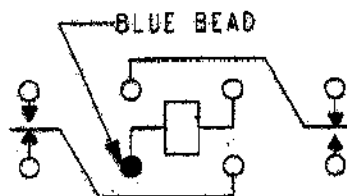

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 2A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 9/21/01

CK. 716 9-24-01

Oil Technologies
 advanced control electronic solutions

CUST. GENICOM
 CUST. NO. 3SAV5542H2 REV.

"HMS" RELAY

HMS1131S10