


CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

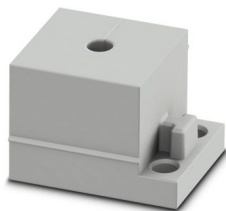

Cable sleeve, small, no. of conductors: 1, type: Round cable, slotted, external cable diameter: 1x 6 mm ... 7 mm, material: SEBS (halogen-free), color: gray, length: 29.5 mm, width: 19.5 mm, height: 17 mm

Product description

Slotted cable sleeve

Commercial data

Item number	0801677
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF67
Product key	BF7CCX
Catalog page	Page 680 (C-2-2019)
GTIN	4046356674836
Weight per piece (including packing)	7.54 g
Weight per piece (excluding packing)	7.54 g
Customs tariff number	40169997
Country of origin	PL

CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>




Technical data

Product properties

Product type	Cable sleeve
No. of conductors	1

Dimensions

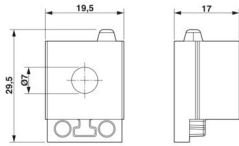Dimensional drawing	
Width	19.5 mm
Height	17 mm
Length	29.5 mm

Material specifications

Material	SEBS (halogen-free)
Flammability rating according to UL 94	V0

Cable/line

External cable diameter	1x 6 mm ... 7 mm
-------------------------	------------------

Characteristics

Seal size	small
Design, Format	Round cable
Design, Cable seal	slotted

Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP54
Ambient temperature (operation)	-40 °C ... 80 °C (static)

CES-STPG-GY-7 - Cable sleeve


0801677

<https://www.phoenixcontact.com/us/products/0801677>



Drawings

Dimensional drawing

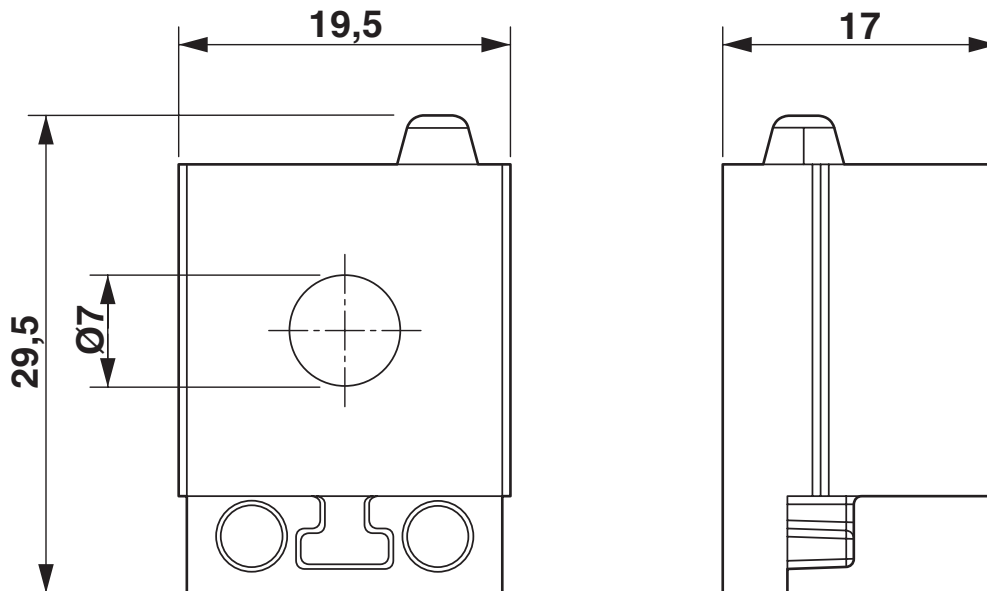

Dimensional drawing

CES-STPG-GY-7 - Cable sleeve



0801677

<https://www.phoenixcontact.com/us/products/0801677>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/0801677>



cUL Recognized
Approval ID: NITW8.E255026



UL Recognized
Approval ID: NITW2.E255026

DNV
Approval ID: TAE00003VJ

cULus Recognized

CES-STPG-GY-7 - Cable sleeve



0801677

<https://www.phoenixcontact.com/us/products/0801677>

Classifications

ECLASS

ECLASS-11.0	27144425
ECLASS-12.0	27144425
ECLASS-13.0	27144425

ETIM

ETIM 9.0	EC000451
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

CES-STPG-GY-7 - Cable sleeve



0801677
<https://www.phoenixcontact.com/us/products/0801677>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>



Accessories

KDT-ST 7 - Filler plug

3063963

<https://www.phoenixcontact.com/us/products/3063963>



Filler plug, material: PA, length: 25 mm, diameter: 7 mm

CES-B10-HFFS-PLBK - Sealing frame

0801663

<https://www.phoenixcontact.com/us/products/0801663>



Sealing frame, With locking latch, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>



CES-B16-HFFS-PLBK - Sealing frame

0801662

<https://www.phoenixcontact.com/us/products/0801662>



Sealing frame, With locking latch, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

CES-B24-HFFS-PLBK - Sealing frame

0801661

<https://www.phoenixcontact.com/us/products/0801661>



Sealing frame, With locking latch, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>



CES-B10-SFFS-PLBK - Sealing frame

0801660

<https://www.phoenixcontact.com/us/products/0801660>



Sealing frame, with screw locking, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

CES-B16-SFFS-PLBK - Sealing frame

0801659

<https://www.phoenixcontact.com/us/products/0801659>



Sealing frame, with screw locking, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

CES-STPG-GY-7 - Cable sleeve

0801677

<https://www.phoenixcontact.com/us/products/0801677>



CES-B24-SFFS-PLBK - Sealing frame

0801658

<https://www.phoenixcontact.com/us/products/0801658>



Sealing frame, with screw locking, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com