

## IP Protected Connectors - Termination Components IP67 Variant 4



part no.  
color  
type  
type 2  
EAN


### E-DAT Industry IP67 V4 metal outlet

IP67 wall outlets offer flexible connection facilities for networks in industrial environments.


- variant 4
- for wall or floor mounting
- Al-Si 12 aluminum housing
- durable powder coating in RAL 7001
- with 1 or 2 ports
- straight or angled cable infeed and outfeed
- dimensions 1port unit: 75 x 78 x 57 mm (without flanges and screwing)
- dimensions 2port unit: 124 x 78 x 57 mm (without flanges and screwing)
- empty – without inserts
- fitting inserts: E-DAT Industry RJ45 field jack insert (TIA-A, TIA-B or Profinet), E-DAT Industry RJ45 coupler insert, E-DAT Industry USB coupler insert, OpDAT Industry SC-RJ/2SC adapter insert or OpDAT Industry LC-D adapter insert

1401040110ME	1401040220ME	1401040620ME
grey	grey	grey
1 port straight	2 port angled	2 port straight
w/o modules	w/o modules	w/o modules
4250184116394	4250184116400	4250184116417


### Dimensional Drawing

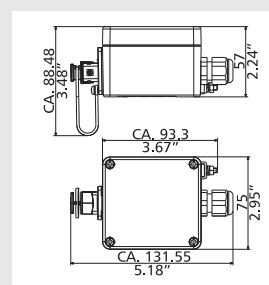

### Dimensional Drawing

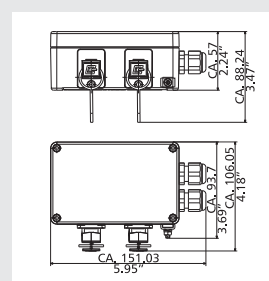

### Dimensional Drawing

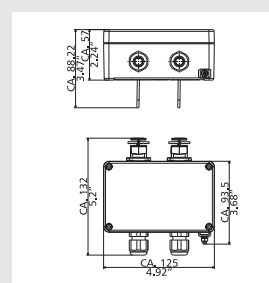

part no.  
color  
type  
type 2  
EAN

### Industry IP67 V4 protective caps

- high protection level even in unplugged condition, thanks to tight IP67 protective cap
- flammability category as per UL 94V-0
- improved resistance to chemicals
- captive protective cap attached
- grip facility for pulling off

1401048002KI	1401048102KI
black	black
plastics	plastics
for plug	for flange
4250184114161	4250184114154