

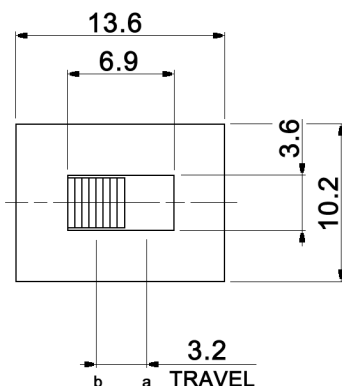
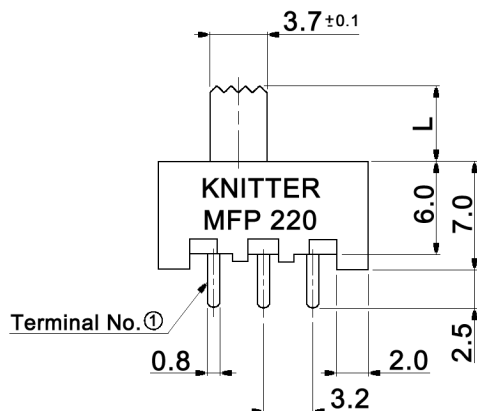


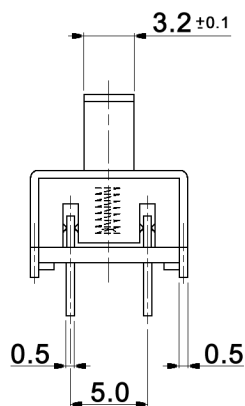


x	L (mm)
none	5
7C	7
8	8

HOLE LAYOUT ± 0.05

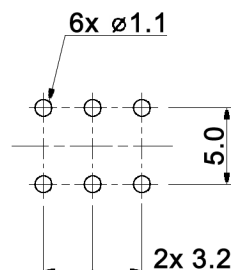

CIRCUIT DIAGRAM

 C: COMMON PIN
BOTTOM VIEW



Specifications:

Contact rating:	350mA, 30V DC
Contact resistance:	20mOhm max.
Insulation resistance:	100MOhm min. at 500V DC for 1 minute
Dielectric strength:	500V AC (50/60Hz, 2mA) for 1 minute
Operating temperature:	-20°C to +85°C
Mechanical life:	10 000 cycles
Operating force:	150 +/-70gf
Soldering conditions:	260 +/-5°C, 5 +/-1sec.
Material:	Terminal: brass strip, silver plated Base: phenolic resin, natural Steel ball: carbon steel, natural Frame: steel, zinc plated Contact clip: phosphor bronze, silver plated Spring: SWC, temper Slider: POM, black



Tolerances: up to 10: ± 0.2 mm
above 10-50: ± 0.3 mm

Date Name
07/10 dr

MFP 220-x

knitter-switch

30 21 33

Page

1/1

Revised 04/11 dr
Modifications Date Name