




+ FIBER OPTICS

FIBER OPTIC PATCH CABLE ASSEMBLIES

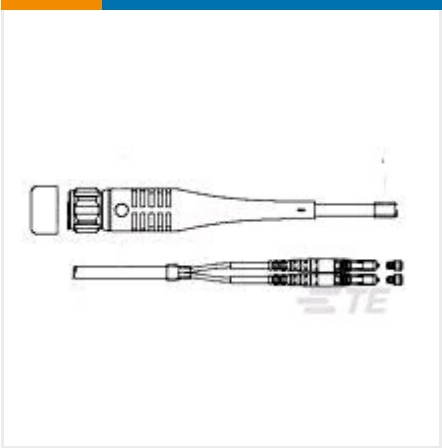

☒ Obsolete

TE CONNECTIVITY (TE)
FOMM50 ODC LEAD 5.5 2PLUG-LC/DPX 150M

FullAXS | Fiber Optic , ODC

1-1985845-5
TE Internal Number: 1-1985845-5

Not Yet Reviewed for EU RoHS
Not Yet Reviewed for EU ELV

Cable Type Fiber Optic Cable (FOCAB) ODC
Fiber Diameter (µm) 50/125
Outside Cable Diameter 5.5 mm [.216 in]
Number of Fibers 2
Connector Color (End B) Beige

 **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings

FIBER OPTIC ODC LEAD 2 FOLD PLUG - LC DUPLEX MULTI MODE 50/125, LONG
PDF
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.
Please Note: Use the Product Drawing for all design activity.

Product Type Features

Cable Type Fiber Optic Cable (FOCAB) ODC
Mode Multimode
Connector Type (End A) Fiber Optic Kit (FOKIT) ODC
Connector Type (End B) LC
Connector Style (End A) Plug
Connector Style (End B) Duplex
Fiber Channel No
Product Type Cable Assembly
Cable Assembly Type Fiber Optic Kit (FOKIT) ODC to LC Duplex

Configuration Features

Number of Fibers 2
Cable Buffering Tight Buffer
Number of Connectors (End B) 2

Signal Characteristics

Return Loss (dB) 20

Body Features

Connector Color (End B) Beige
Cable Color Black
Boot Type (Left) ODC
Boot Type (Right) Bend Limiting
Boot Color (Left) Black
Boot Color (Right) Beige
Ferrule Material Ceramic

Dimensions

Fiber Diameter (µm) 50/125
Outside Cable Diameter 5.5 mm [.216 in]

PRODUCT COMPLIANCE

+

Statement of Compliance

Statement of Compliance
PDF