
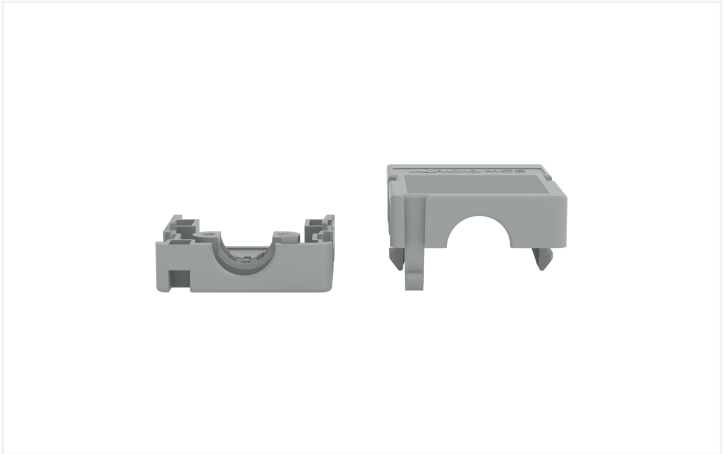



Data Sheet | Item Number: 232-664

Strain relief housing; for female and male connectors; 2 parts; Pin spacing 7.5 mm; 4-pole; gray

<https://www.wago.com/232-664>

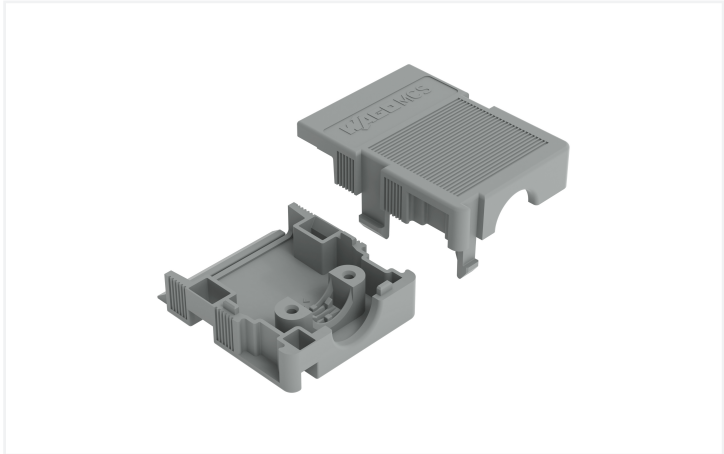

Color: ■ gray

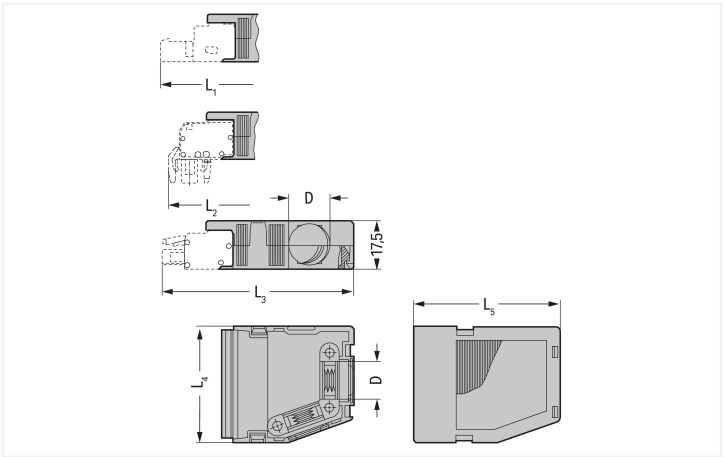

Dimensions in mm
2-pole; only suitable for cable ties; 1 cable outlet (rear side), max. cable tie width 3.6 mm; 3- to 4-pole; suitable for cable clamp; 1 x cable outlet (rear side); 5-pole; suitable for cable clamp; 1 x cable outlet (rear side) and 1 x cable outlets (side); 1 cover (included) 7-pole; suitable for cable clamp; 1 x cable outlet (rear side) and 2 x cable outlets (side); 2 covers (included) Cable ties and binding tools are not offered by WAGO.

- Suitable for cable clamp
- 1 x cable outlet, rear

Connection Data	
Connection 1	
Pole number	4



Physical data	
Pin spacing	7.5 mm / 0.295 inches
Width	30.5 mm / 1.201 inches
Height	17.5 mm / 0.689 inches
Depth	33 mm / 1.299 inches

Mechanical data	
Suitable	for standard male and female connectors

Material data	
Note (material data)	Information on material specifications can be found here
Color	gray
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.243 MJ
Weight	7.1 g

Commercial data	
Product Group	3 (Multi Conn. System)
PU (SPU)	25 pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332371827
Customs tariff number	39269097900

Product Classification	
UNSPSC	39121421
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-44-04-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Approvals / Certificates

Approvals for marine applications



Approval	Standard	Certificate Name
ABS American Bureau of Ship- ping	-	24-0095975-PDA



Downloads

Environmental Product Compliance

Compliance Search			
Environmental Product Compliance 232-664			↓

Documentation

Additional Information			
Technical Section	03.04.2019	pdf 2027.26 KB	↓

CAD/CAE-Data

CAE data			
EPLAN Data Portal 232-664			↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Installation

1.1.1.1 Mounting accessories



Item No.: 209-177 Cable clamp; for strain relief; 4- to 6-pole	Item No.: 209-176 Fixing screws; for cable clamp; 4- to 6-pole
--	--

1.1.2 Marking

1.1.2.1 Marker



Item No.: 793-5501/000-006 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; blue



Item No.: 793-5501/000-014 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; brown
--



Item No.: 793-5501/000-007 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; gray



Item No.: 793-5501/000-023 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; green
--



Item No.: 793-5501/000-017 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; light green
--



Item No.: 793-5501/000-012 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; orange



Item No.: 793-5501/000-005 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; red
--



Item No.: 793-5501/000-024 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; violet



Item No.: 793-5501 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; white
--



Item No.: 793-5501/000-002 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; yellow



Item No.: 793-501/000-006 WMB marking card; as card; not stretchable; plain; snap-on type; blue



Item No.: 793-501/000-007 WMB marking card; as card; not stretchable; plain; snap-on type; gray



1.1.2.1 Marker



Item No.: 793-501/000-023
WMB marking card; as card; not stretchable;
plain; snap-on type; green



Item No.: 793-501/000-017
WMB marking card; as card; not stretchable;
plain; snap-on type; light green



Item No.: 793-501/000-012
WMB marking card; as card; not stretchable;
plain; snap-on type; orange



Item No.: 793-501/000-005
WMB marking card; as card; not stretchable;
plain; snap-on type; red



Item No.: 793-501/000-024
WMB marking card; as card; not stretchable;
plain; snap-on type; violet



Item No.: 793-501
WMB marking card; as card; not stretchable;
plain; snap-on type; white



Item No.: 793-501/000-002
WMB marking card; as card; not stretchable;
plain; snap-on type; yellow



Item No.: 2009-115/000-006
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; blue



Item No.: 2009-115/000-007
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; gray



Item No.: 2009-115/000-023
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; green



Item No.: 2009-115/000-017
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; light green



Item No.: 2009-115/000-012
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; orange



Item No.: 2009-115/000-024
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; violet




Item No.: 2009-115
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; white



Item No.: 2009-115/000-002
WMB-Inline; for Smart Printer; 1500 pieces
on roll; stretchable 5 - 5.2 mm; plain; snap-
on type; yellow


Installation Notes

Application

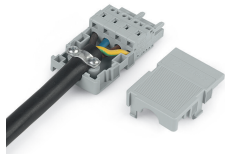


2- to 3-pole; only suitable for cable ties; max.
3.6 mm cable tie width
4- to 16-pole; suitable for cable clamp, cov-
ers (included)
Cable ties and binding tools are not offered
by WAGO.


Installation

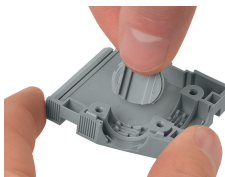

Snapping a cover into the unused cable out-
let.

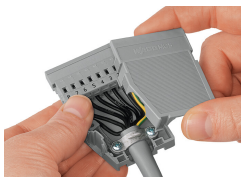

Strain relief housing shown with a male con-
nector equipped with CAGE CLAMP®

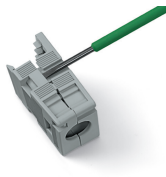

Disassembling a strain relief housing is only
possible using an operating tool (e.g.,
210-719).