






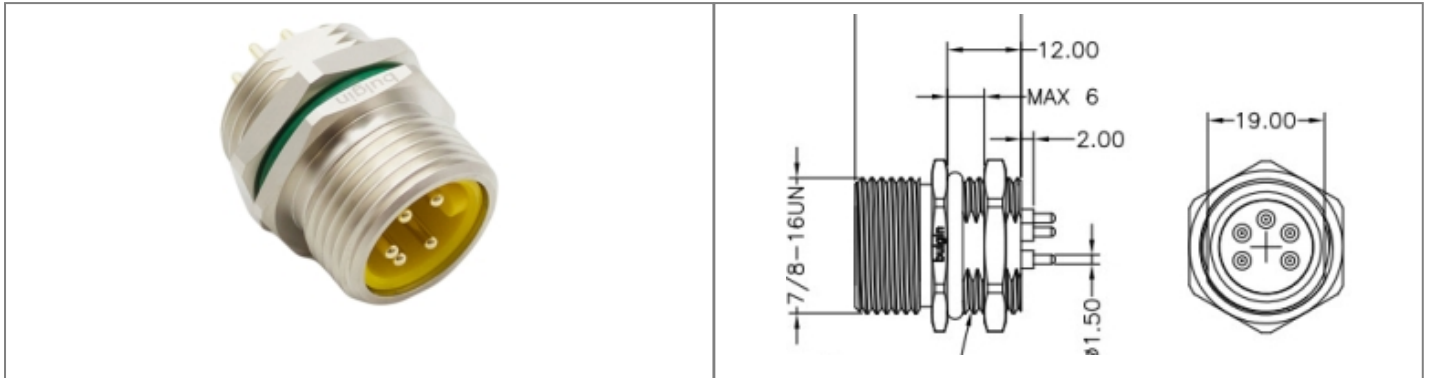

**Product Name // 5 Contacts 7/8" Front Panel Mounting  
Male Connector**
 [View Product Page](#)

**// Product Description:**

-  3 Contacts 7-8" Front Panel Mounting Male Connector
-  IP67 rated when mated
-  Mechanical Cycles >100
-  Operating Temperature -25°C to +85°C
-  Rated Voltage 300 V
-  ROHS compliance

**// General Information:**

Product Display Title:	7/8" Front Panel Mounting Male Connector
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Connection Method:	PCB
Contact Pin Material:	Brass gold plated 1u"
Contact Type:	Plug Contact
Current Max:	9A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6.0mm
Number Of Contacts:	5 Contacts
Panel Cut Out:	22.20mmx19.20mm
Pcb Thickness:	>2.5mm
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

**// Product PDF Links**
 [78 Series Circular connectors...](#)
**// Product 3D CAD Model Links**
 [PXMBNI78FPM05APC78 3D CAD Model](#)