


365016-1 Product Details

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

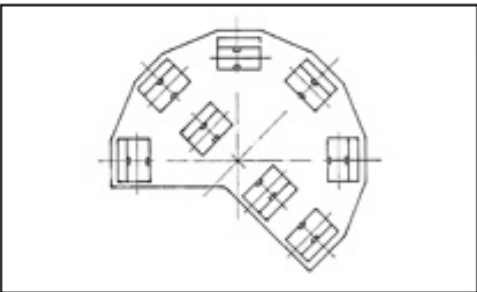

365016-1

TE Part Number: 365016-1

 **Active**

 [Add to Part List](#)

Positive Lock Connectors

 [Always EU RoHS/ELV Compliant](#) (Statement of Compliance)

Product Highlights:

- Receptacle Housing
- Tab Fit = 6.35 mm
- Line = Mark I
- Receptacle Style = Straight
- Number of Positions = 8

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [8 POSN POSITIVE LOCK HSG](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Receptacle Housing
- [Tab Fit \(mm \[in\]\)](#) = 6.35 [.250]
- [Receptacle Style](#) = Straight
- Number of Positions = 8
- [Color](#) = Black
- [Material](#) = Polyamide 6.6
- [Keyed](#) = No

Body Related Features:

- [Position Keyed](#) = None
- Flammability Rating = UL 94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- [Line](#) = Mark I
- Brand = AMP