


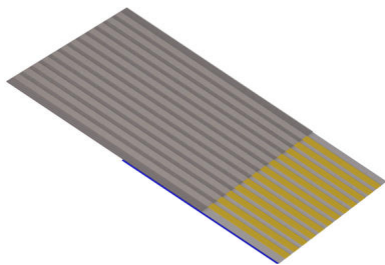

Part Number : [151200121](#)
Product Description : 0.50mm Pitch Premo-Flex FFC
Jumper, Same Side Contacts (Type A), 76.00mm Cable
Length, Gold (Au) Plating, 12 Circuits
Series Number : 15120
Status : Active
Product Category : Flat-Flexible Cable (FFC)



Documents and Resources

Drawings

- [151200121 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Specifications

- [151200001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains 1,1'-(Ethane-1,2-diyl)bis[pentabromobenzene] per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15120
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 76.00mm Cable Length, Gold (Au) Plating, 12 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	196823478437

Electrical

Current - Maximum per Contact	0.35A
Voltage - Maximum	60V AC

Physical

Cable Length	76.00mm
Circuits (Loaded)	12
Contact Layout Type	A (same side)
Design Feature	Ultra-Flexible
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Net Weight	0.183/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm

Temperature Range - Operating	-40° to +125°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flexible Cable (FFC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 12 Circuits, Gold Plating	<u>525591252</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 12 Circuits, Gold Plating	<u>527451297</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 12 Circuits, Gold Plating	<u>527461271</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 12 Circuits, Gold over Nickel Plating	<u>5034801200</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 12 Circuits, Gold over Nickel Plating	<u>5051101292</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Dual Contact Style, 1.20mm Mated Height, 12 Circuits, Gold (Au) Plating	<u>512811298</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.20mm Height,	<u>545481272</u>

Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Plating	
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Top Contact Style, 12 Circuits, Gold (Au) Plating	<u>545501272</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 12 Circuits	<u>781191220</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 12 Circuits	<u>781271220</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 12 Circuits, Phosphor Bronze, Gold Plating	<u>5019511230</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 12 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<u>5019511250</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Contact Plating	<u>512961294</u>

This document was generated on May 20, 2026