




UB3 CONNECTOR

USB (Universal Serial Bus) Conforming Connector

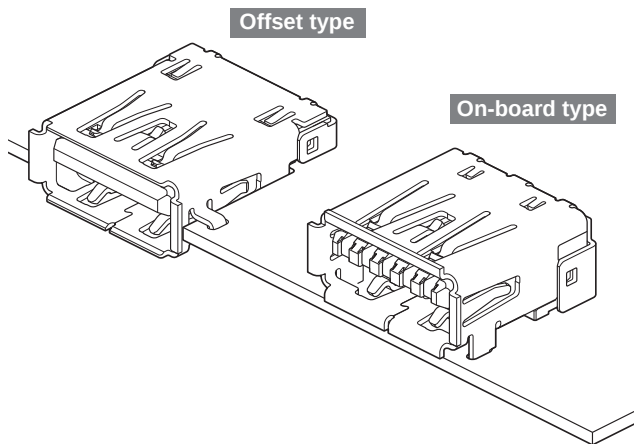

This connector is an interface connector conforming to USB (Universal Serial Bus) 3.0 Standard.

- Shell strong structure
- Reverse of side spring
- Halogen-free

Specifications

- Current rating: VBUS & GND circuits (No.1 & 4 circuits)
/ 1.8 A AC, DC
Other circuits (No. 2, 3, 5 to 9 circuits)
/ 0.25 A AC, DC
- Voltage rating: 30 V AC, DC
- Temperature rang: -25°C to +85°C
(including temperature rise in applying electrical current)
- Contact resistance: Initial value/ 30 mΩ max.
After environmental tests/ 10 mΩ max.
(variation from initial value)
- Insulation resistance: 100 MΩ min.
- Withstanding voltage: 100 VAC/minute
- Applicable PC board: Double-sided through-hole PCB
(Unusable one-side PCB)
112 & 333 types/ t1.0 mm
414 type/ t1.6 mm

* Refer to "General Instruction and Notice when using Terminals and Connectors" at the end of this catalog.

* Contact JST for details.

* Compliant with RoHS.

Standards


Recognized E60389

Receptacle

Type A

Normal On-board type (for PC board thickness t1.0 mm)

TID No. : 360000071

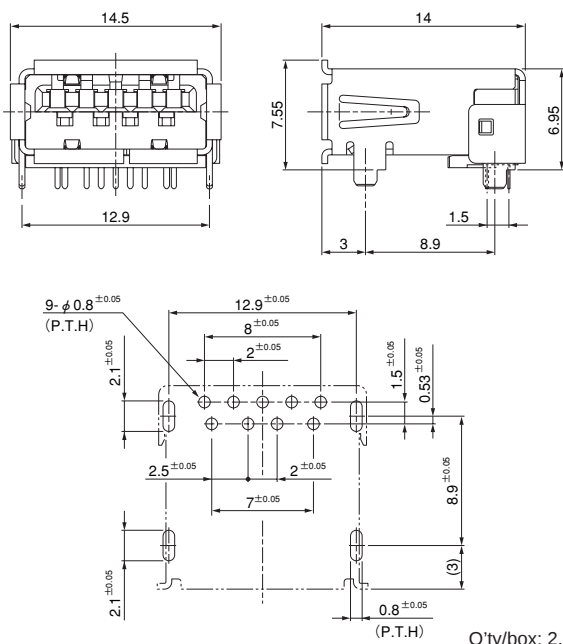


Q'ty/box: 2,618

Type A

Normal Offset type (for PC board thickness t1.0 mm)

TID No. : 360000070

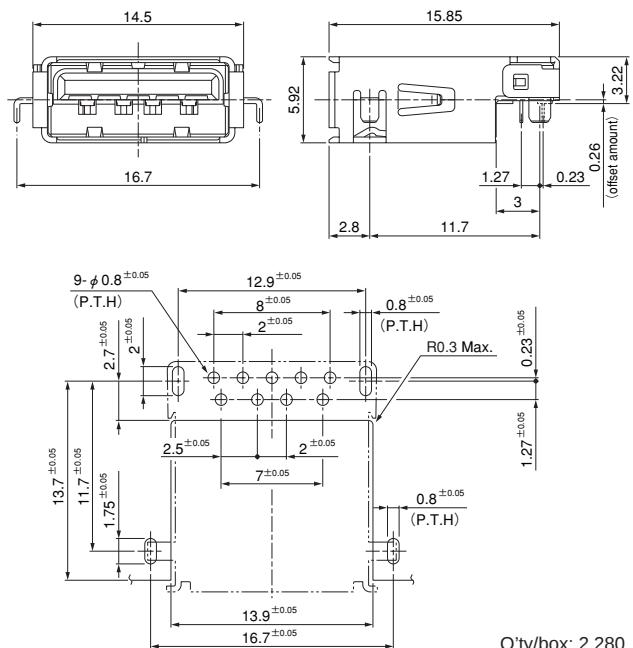

Q'ty/box: 2,280

Model No.	Material and Finish
UB3A-9R-D6C-112(HF)	Contact A, B: Copper alloy, nickel-undercoated, selective nickel-palladium alloy-plated, gold-plated Housing: Heat resisting resin, UL94V-0, blue Shell: Stainless steel, nickel-undercoated, tin-plated

RoHS compliance

Note: The dimensions above should serve as a guideline. Contact JST for details.

Model No.	Material and Finish
UB3A-9R-D6C-333(HF)	Contact A, B: Copper alloy, nickel-undercoated, selective nickel-palladium alloy-plated, gold-plated Housing: Heat resisting resin, UL94V-0, blue Shell: Stainless steel, nickel-undercoated, tin-plated

RoHS compliance


Note: The dimensions above should serve as a guideline. Contact JST for details.

Receptacle

Type A

Normal On-board type (for PC board thickness t1.6 mm)

TID No. : 360000071

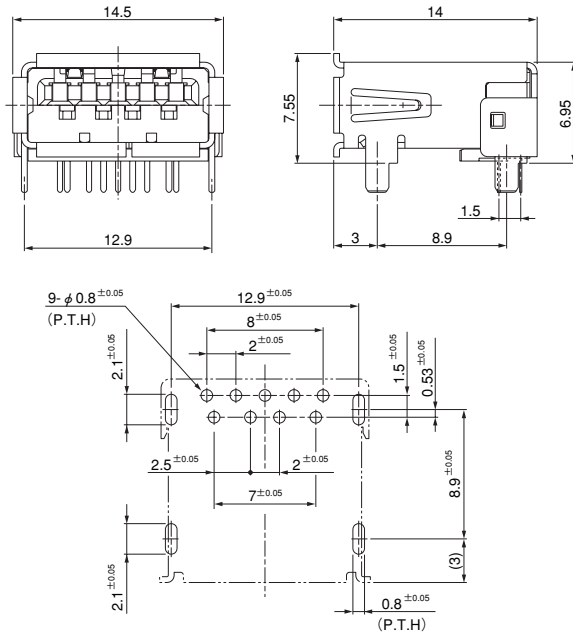

Model No.	Material and Finish
UB3A-9R-D6C-414(HF)	Contact A, B: Copper alloy, nickel-undercoated, selective nickel-palladium alloy-plated, gold-plated Housing: Heat resisting resin, UL94V-0, blue Shell: Stainless steel, nickel-undercoated, tin-plated

RoHS compliance

Note: The dimensions above should serve as a guideline. Contact JST for details.