


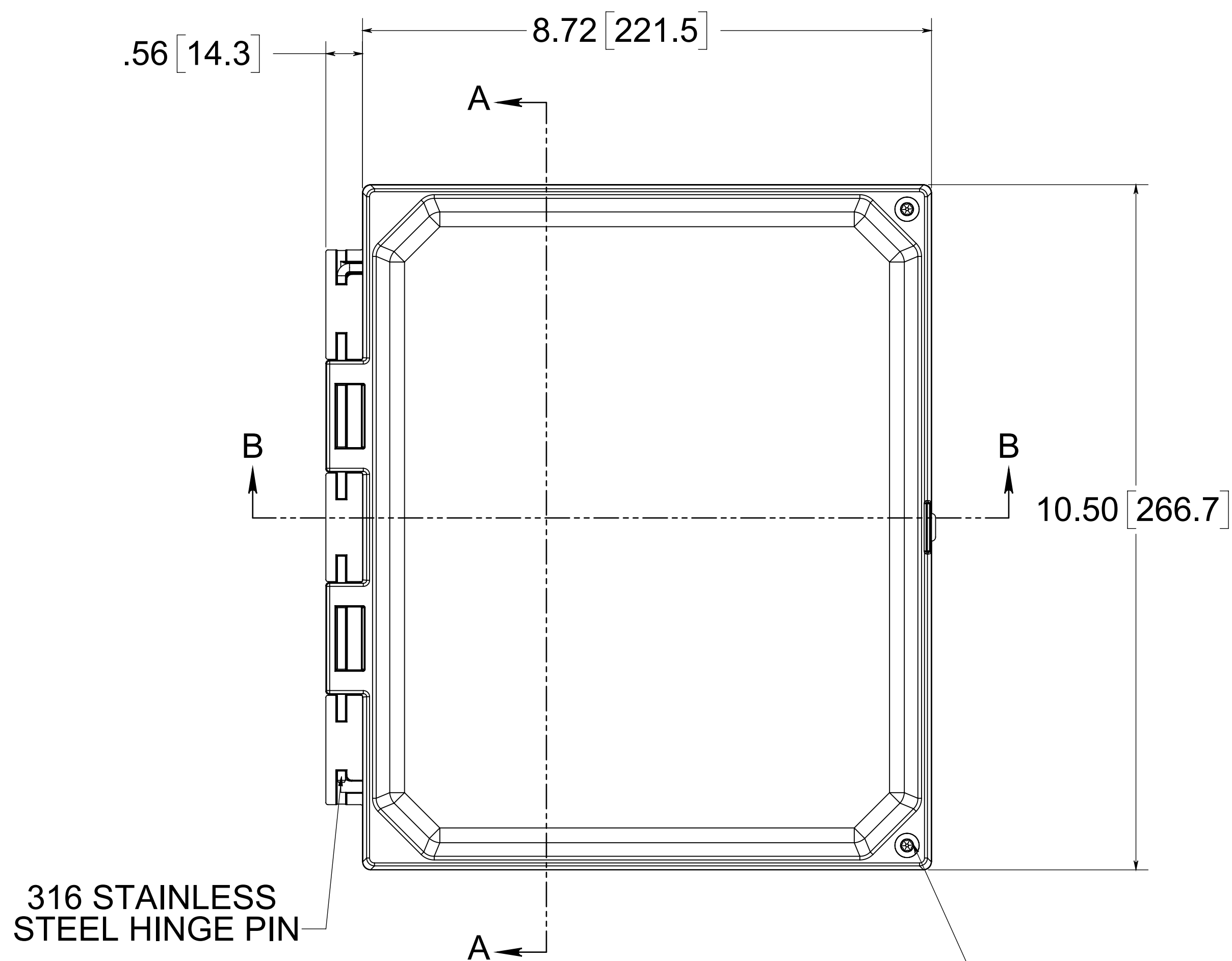

(2) EACH #10-32 BRASS INSERTS, AND 316 STAINLESS STEEL CAPTIVE TAMPER PROOF SCREWS WITH O-RINGS


FIP POLYURETHANE GASKET

.145 [3.7]

SECTION B-B
SCALE 1 : 1.5



FIP POLYURETHANE GASKET

MATERIAL:
BOX- INJECTION POLYCARBONATE
STANDARD COVER- INJECTION POLYCARBONATE
CLEAR COVER-INJECTION POLYCARBONATE

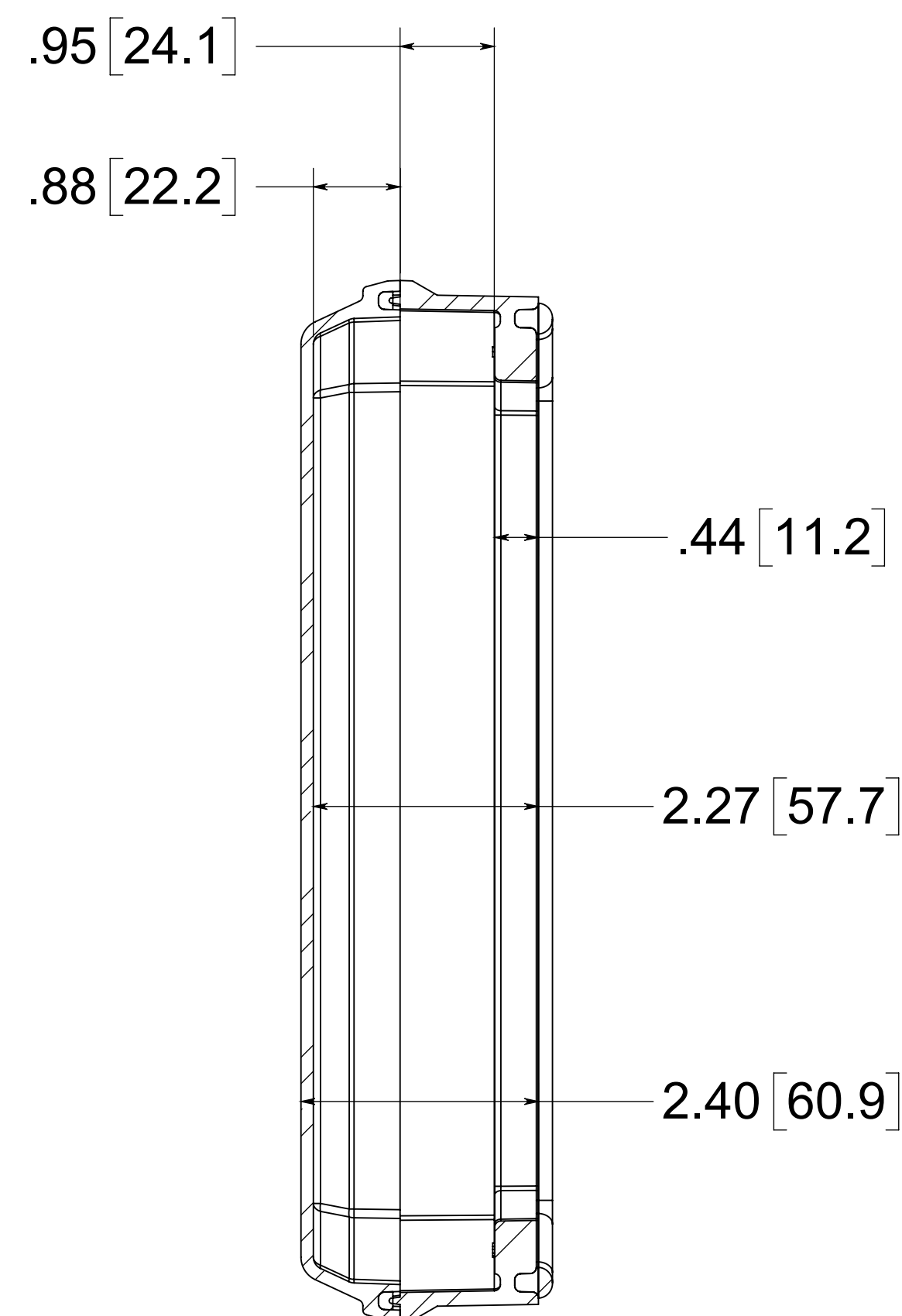


SECTION A-A

Ø .23 [5.8]

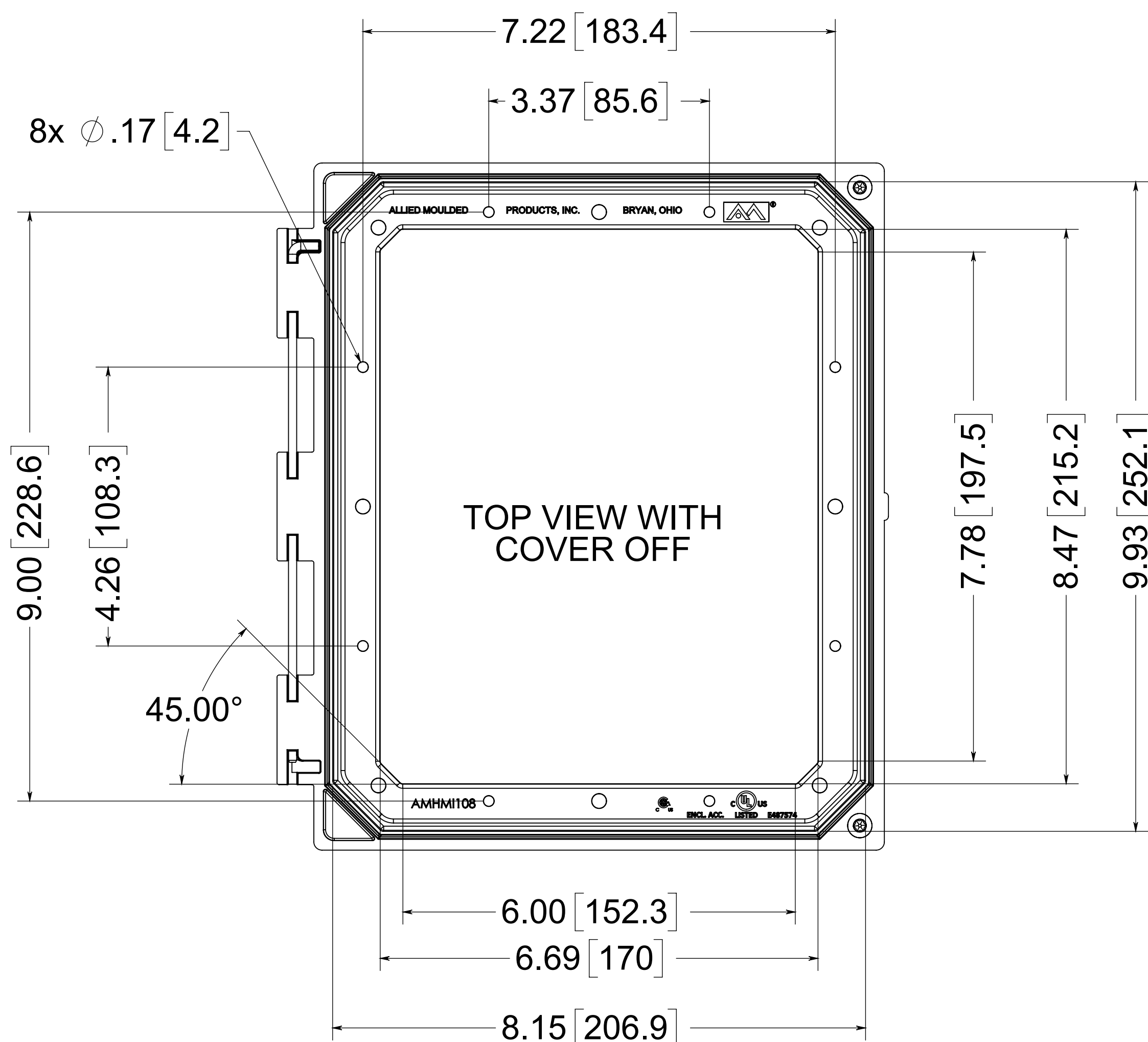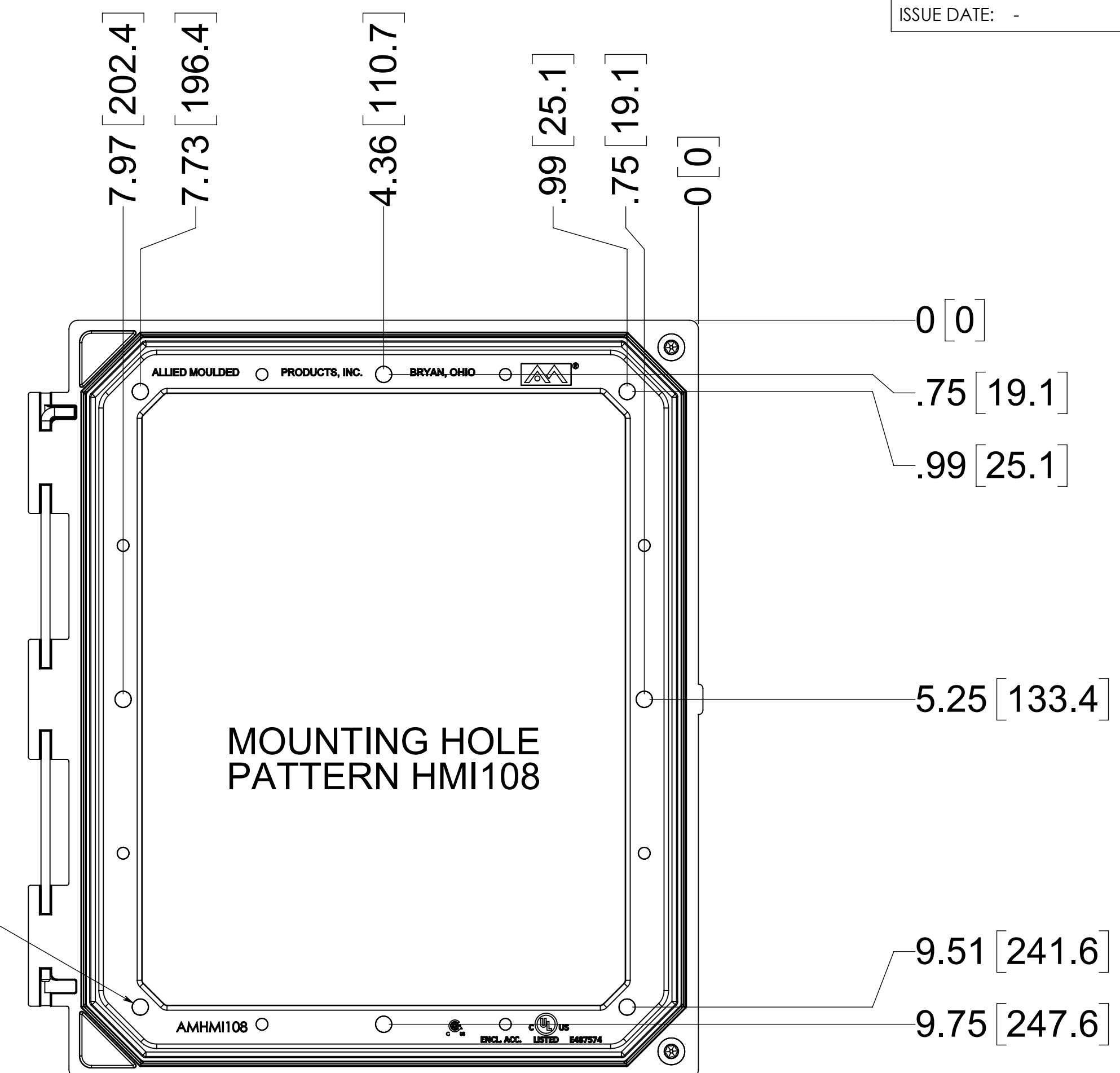

NOTE:
1. DATA SUBJECT TO CHANGE
2. WILL FIT ENCLOSURE
SIZES 12X10 AND LARGER

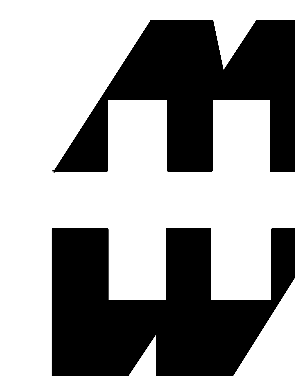

PART No. PJHMI108CCHTP

for more information visit
www.hammfg.com
Data subject to change without notice
Drawing Not to Scale