

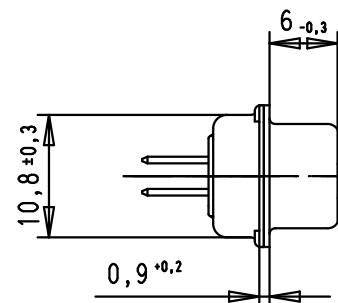


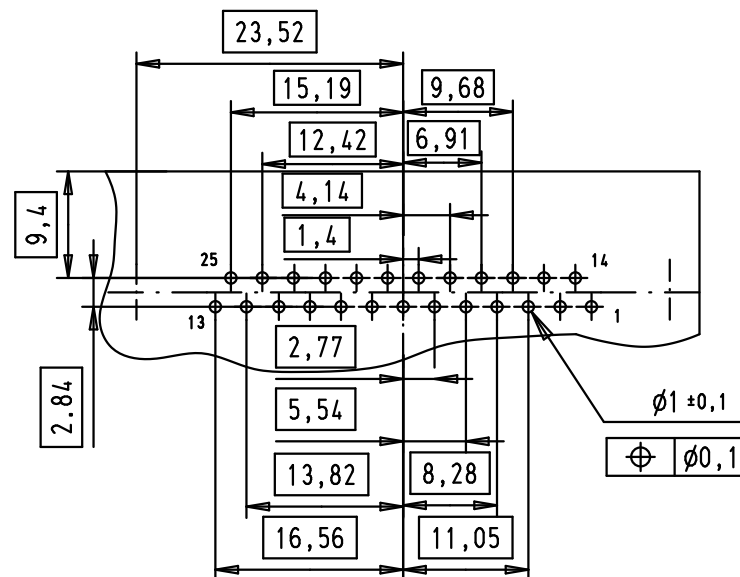

Performance level	PL2
Filter type	C
Capacitance	1000pf±20%
Working Voltage	100v
Current Rating	7.5A
Insulation Resistance	>1GΩ

FREQUENCY (MHz)	ATTENUATION (dB)
5	1dB
10	3dB
50	12dB
100	20dB
500	34dB
1000	30dB

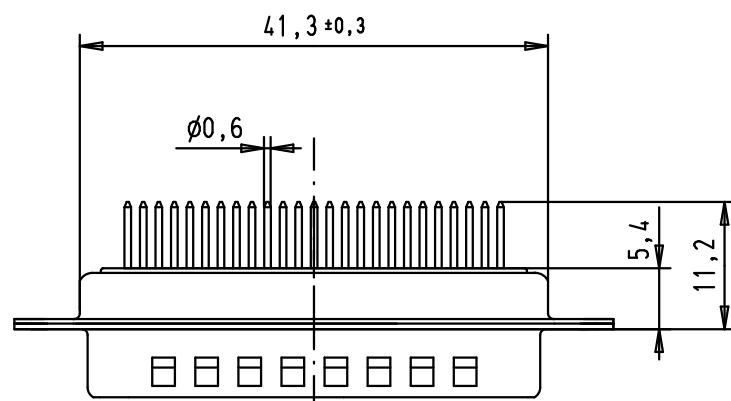

				Dat.	Name	 All Dim. in mm Orig. Size DIN A 4	D-Sub, male, straight, 25 Poles, turned solder pin, dimples and fixing holes	No?Mstab/ Scale 1.5:1
			Detail.	8-JUL-02	CV			
36283	09/12/11	SD	Insp.	09/12/11	JB			
33423	06/02/06	JMDR	Stand.					
32234	06/10/04	TR					TB 09643227230	Blatt/ Page 1 / 1
31058	8-JUL-02	CV						
Mod.	Dat.	Name						
HARTING EURL F-95972 Paris								