

MODEL TL-5276/W



For Utility Metering Memory Back-up Applications

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)




■ Nominal capacity @ 1 mA, to 2V	1.0 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	50 mA
■ Maximum pulse current capability	100 mA
■ Enclosure	Lexan 143 UV stable
■ Operating temperature range	-55°C to +85°C
■ U.L. Component Recognition, MH 12193	

TADIRAN LITHIUM BATTERIES

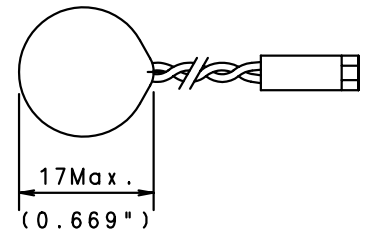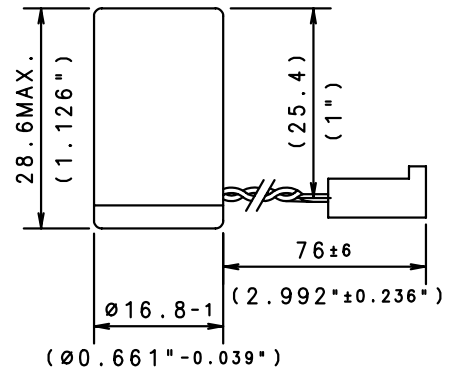

ADDITIONAL INFORMATION

CONNECTOR TYPE	MOLEX P/N 22-01-3027 OR COMPATIBLE
CATALOGUE NO.	15-5276-30000

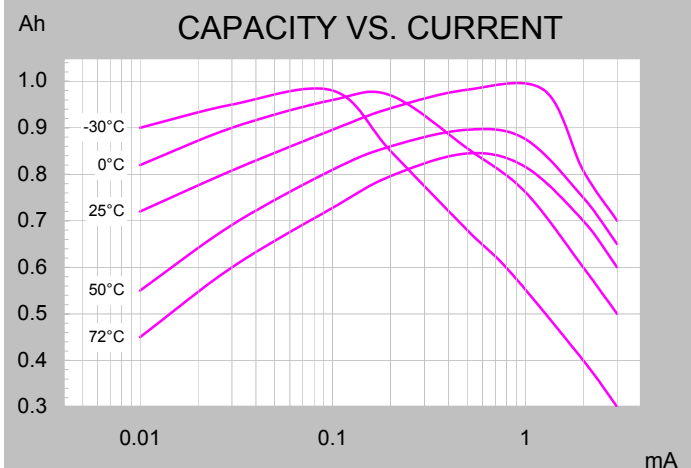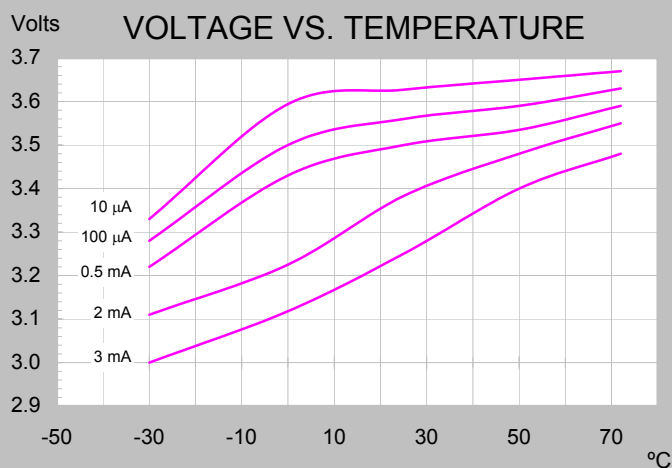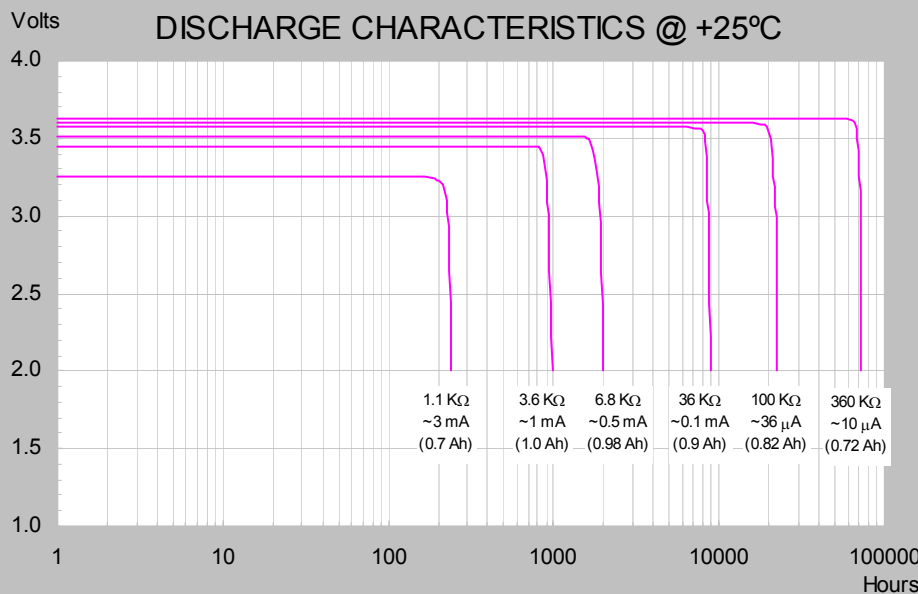

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.

ECN 1501445 Rev. D. 01/2007