


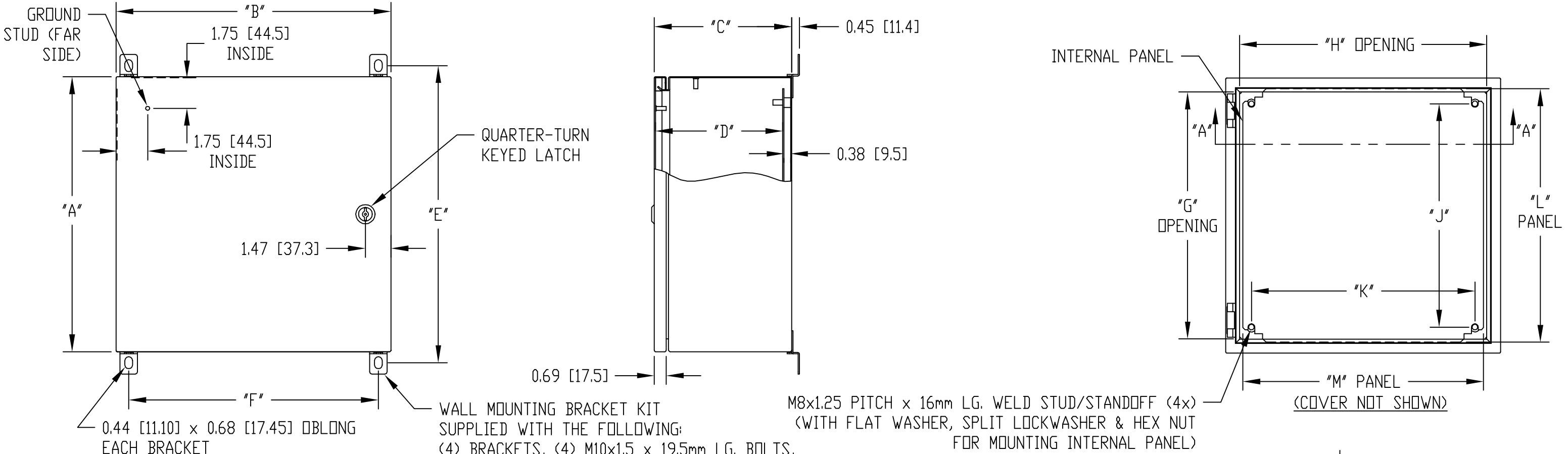

MATERIAL:
BODY & COVER - 16 GA. [1.5mm] TYPE 304 STAINLESS STEEL
INTERNAL PANEL - 14 GA. [2.0mm] C.R.S.
WALL MTG. BRKTS - 14 GA. [2.0mm] TYPE 430 STAINLESS STEEL
STRIKER - C.R.S.
HINGE PINS & WALL MTG. HARDWARE - TYPE 201 STAINLESS STEEL
LATCH - ZINC DIE CAST
GASKET - 0.38 [9.5] THK. ROGERS CORP. PORON #4701-30-15375-04 (BLACK)
SEALING WASHERS - BLACK NEOPRENE
HOLE PLUGS - LIGHT GRAY NEOPRENE

FINISH:
BODY & COVER - NATURAL, OUTSIDE SURFACES POLISHED
INTERNAL PANEL - ZINC PLATED
WALL MOUNTING BRACKETS & HINGE PINS - NATURAL
STRIKER - ZINC PLATED
LATCH - CHROME PLATED

M8x1.25 PITCH x 16mm LG. WELD STUD/STANDOFF (4x)
(WITH FLAT WASHER, SPLIT LOCKWASHER & HEX NUT FOR MOUNTING INTERNAL PANEL)

M6x1.0 PITCH x 16mm LG. WELD STUD (FOR GROUNDING)
(SAME STUD IN COVER)

BOXES SUPPLIED WITH GROUNDING KIT THAT CONTAINS THE FOLLOWING: (1) GROUND WIRE, (4) FLAT WASHERS, (2) SPLIT LOCKWASHERS AND (2) HEX NUTS

PART NO.	"A"	"B"	"C"	"D"	"E"	"F"	"G"	"H"	"J"	"K"	"L"	"M"
SNB-3730-SS	9.84 [250]	7.87 [200]	5.91 [150]	5.33 [135.4]	11.12 [282.3]	6.42 [163]	8.25 [209.6]	6.28 [159.6]	6.89 [175]	4.92 [125]	8.46 [215]	5.91 [150]
SNB-3738-SS	7.87 [200]	5.91 [150]	5.91 [150]	5.33 [135.4]	9.15 [232.3]	4.45 [113]	6.28 [159.6]	4.31 [109.6]	4.92 [125]	2.95 [75]	6.50 [165]	3.94 [100]
SNB-3739-SS	7.87 [200]	7.87 [200]	3.98 [101]	3.40 [86.4]	9.15 [232.3]	6.42 [163]	6.28 [159.6]	6.28 [159.6]	4.92 [125]	4.92 [125]	6.50 [165]	5.91 [150]
SNB-3740-SS	9.84 [250]	9.84 [250]	5.91 [150]	5.33 [135.4]	11.12 [282.3]	8.39 [213]	8.25 [209.6]	8.25 [209.6]	6.89 [175]	6.89 [175]	8.46 [215]	7.87 [200]
SNB-3741-SS	9.84 [250]	7.87 [200]	3.98 [101]	3.40 [86.4]	11.12 [282.3]	6.42 [163]	8.25 [209.6]	6.28 [159.6]	6.89 [175]	4.92 [125]	8.46 [215]	5.91 [150]