

MODEL TL-4930


International size reference: D, ER32L615

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)




■ Nominal capacity @ 4 mA, to 2 V	19 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	100 mA
■ Maximum 1 sec. pulse capability	250 mA
■ Weight	93 g (3.28 oz)
■ Volume	51 cc
■ Operating temperature range	-55 °C to +85 °C
■ U.L. Component Recognition, MH 12193	

***TADIRAN
LITHIUM
BATTERIES***

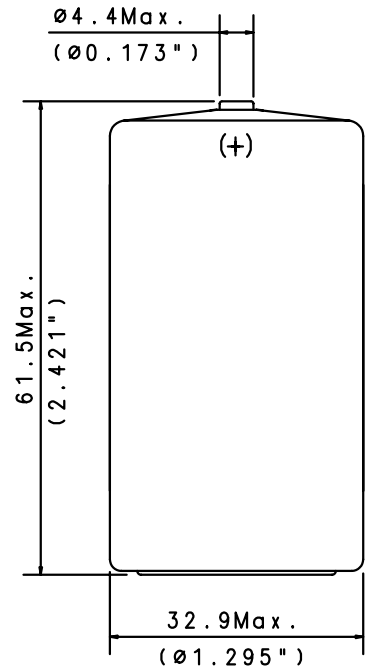

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-4930-21000
SUFFIX- /T SOLDER TABS	15-4930-31000

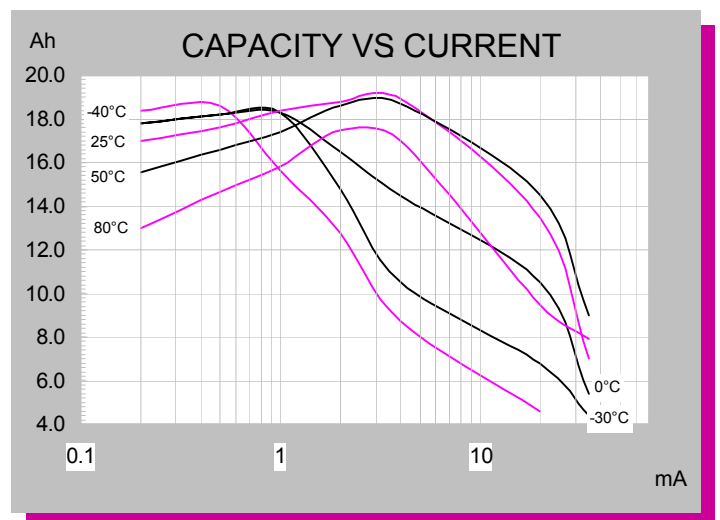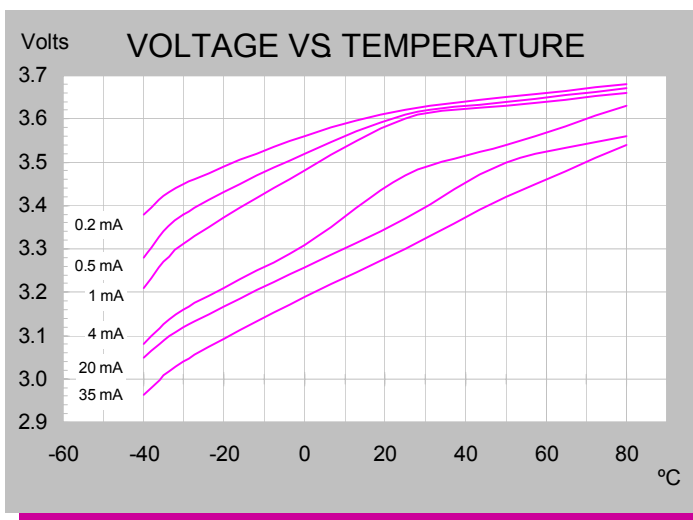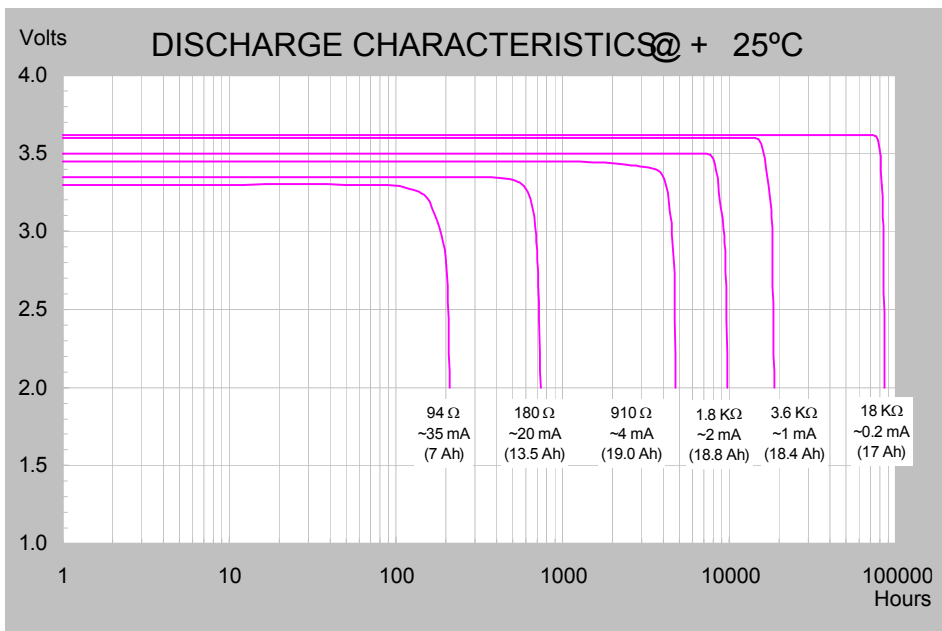

XOL - Extended Operating Life

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.
ECN 1502401 Rev. E 01/2012