

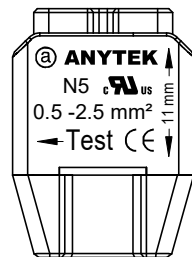


RoHS Compliant

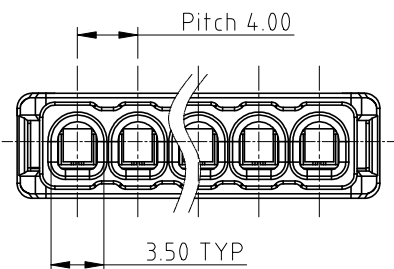



2P

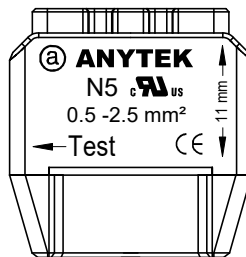

3P

Electrical:

- Voltage rating: 300 V
- Current rating: 24 A
- Wire range(Solid wire AWG): 18-12 AWG
- Wire strip length: 11 mm
- Withstanding Voltage: 2.5KV
- Insulation Resistance: DV500V 500MΩ min
- Operating temperature: -40°C to +80°C
- Safety Approval: cULus

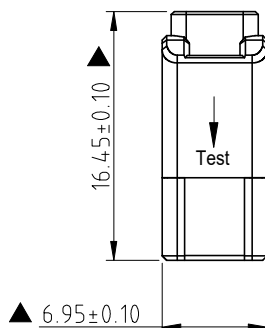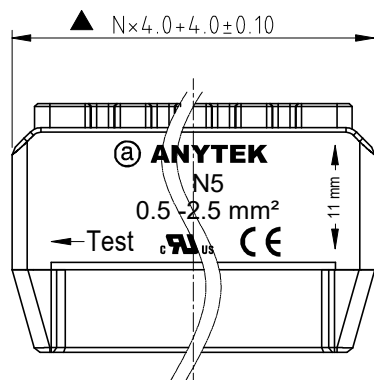

Part No. N5xx00x00000G



NO. OF POLES

- 02: 2 POLES
- 03: 3 POLES
- 04: 4 POLES
- 05: 5 POLES

Body Color:

- 3 Orange(RAL2011/P)
- 4 Yellow(RAL1018/A)
- 5 Green(RAL6018/T)

RoHS compliant  
(lead<4%)  
In copper Alloy

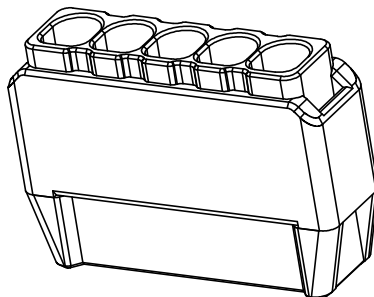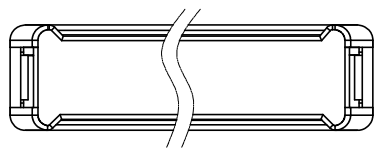

**Amphenol**  
**ANYTEK**

**CUSTOMER COPY**

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATSOEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

|          |               |                                |                    |          |              |            |
|----------|---------------|--------------------------------|--------------------|----------|--------------|------------|
| TITLE    |               | N5 Series ,pitch 4.00mm,T=6.95 |                    |          |              |            |
| PART NO. | N5xx00x00000G |                                |                    | DWG NO.  | 8N50001      |            |
| APPROVED | CHECKED       | DESIGNED                       | DRAWN              | CUST NO. |              |            |
|          |               | LENA<br>2021.01.07             | LENA<br>2021.01.07 |          | UNIT: mm     | X. ±0.50   |
|          |               |                                |                    |          | SCALE: 2:1   | X.X ±0.30  |
|          |               |                                |                    |          | REV.: A0     | X.XX ±0.10 |
|          |               |                                |                    |          | SHEET: 01/01 | X° ±1°     |