

H4X:C5FF:UCFM:AC - Housing

1415793

<https://www.phoenixcontact.com/us/products/1415793>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



HEAVYPORT B24 panel mounting base, with single locking latch, with plastic protective cover, with stainless steel front plate connections, 1x RJ45 CAT5e (female/female), 1x USB Type A/A (female/cable), 1x 120 V AC outlet

Your advantages

- Good shielding in the event of electromagnetic interference

Commercial Data

Item number	1415793
Packing unit	1 pc
Sales Key	BF69
Product Key	BF7EGX
GTIN	4055626805894
Weight per Piece (including packing)	22.22 g
Weight per Piece (excluding packing)	22.22 g
Country of origin	US

H4X:C5FF:UCFM:AC - Housing



1415793

<https://www.phoenixcontact.com/us/products/1415793>

Technical Data

 
Product properties

Type	B24
Product type	Stackable housing set
Application	Standard
Housing type	Panel mounting base
Protective cover	yes

Electrical properties

Rated voltage (III/3)	max. 125 V AC ()
Rated current	max. 1.5 A DC (RJ45)
	15 A ()

Dimensions

Dimensional drawing	
Width	53 mm
Height	30.5 mm
Length	140.5 mm

Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	113 mm

Material specifications

Color	gray aluminum
Seal material	NBR, conductive
	NBR, conductive
Housing surface material	uncoated
Material, protective cover	PA
Locking latch material	Polyamide
Impact strength	IK08
Housing material	Die-cast aluminum, salt water resistant

Connector

Contact insert design	with 1x RJ45 Cat 5E Ethernet Socket/socket, snap-in slot locking
	with 2x USB Type A/A 2.0
	with 1x 120 V AC outlet Terminal 6.35 mm. AC outlet requires slip-on sleeves: Item No. 3240539 or 3240536

Environmental and real-life conditions

H4X:C5FF:UCFM:AC - Housing

1415793

<https://www.phoenixcontact.com/us/products/1415793>



Ambient conditions

Degree of protection	IP66
	IP67
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C (Housing)

H4X:C5FF:UCFM:AC - Housing


1415793

<https://www.phoenixcontact.com/us/products/1415793>




Drawings

Dimensional drawing

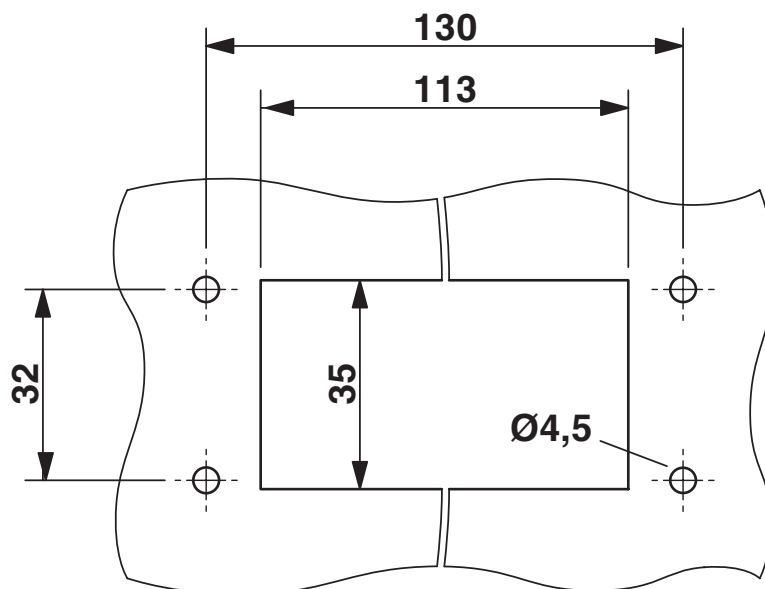

Mounting cutout

Dimensional drawing

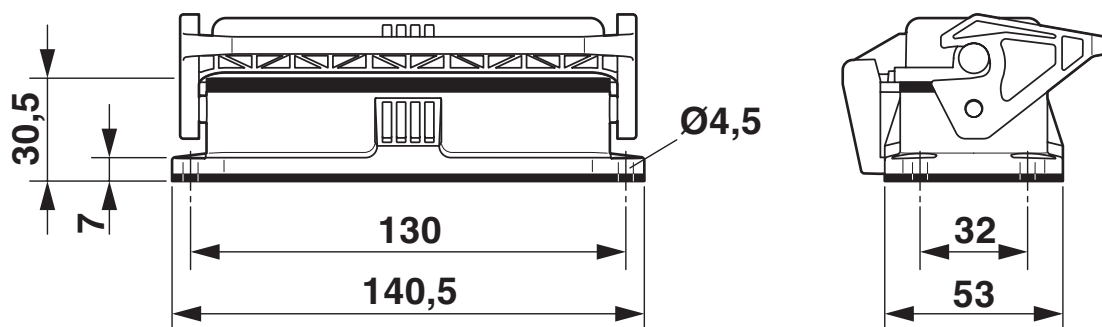

Dimensional drawing

H4X:C5FF:UCFM:AC - Housing

1415793

<https://www.phoenixcontact.com/us/products/1415793>



Classifications

ECLASS

ECLASS-11.0	27440101
ECLASS-12.0	27440113
ECLASS-13.0	27440113

ETIM

ETIM 7.0	EC002636
----------	----------

H4X:C5FF:UCFM:AC - Housing



1415793

<https://www.phoenixcontact.com/us/products/1415793>

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

H4X:C5FF:UCFM:AC - Housing

1415793

<https://www.phoenixcontact.com/us/products/1415793>



Accessories

C-SCFFI 2,5/4,8X0,5 - Connector

3240539

<https://www.phoenixcontact.com/us/products/3240539>



Slip-on sleeve, fully isolated, blue, 1.5 ... 2.5 mm², for plug 4.8 x 0.5 mm

C-SCFFI 1,5/4,8X0,5 - Connector

3240536

<https://www.phoenixcontact.com/us/products/3240536>



Slip-on sleeve, fully isolated, red, 0.5 ... 1.5 mm², for plug 4.8 x 0.5 mm

Phoenix Contact 2023 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com