



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 1746979-1
ECU 121P HDR ASSY-PBT



TE Part # 936054-1
CAVITY PLUG(ECU 40P&81P ASSY)



TE Part # CAT-T4827-T273
TIMER, RECEPTACLE AND TAB



TE Part # 963293-1
SEALING F JPT+2,8



TE Part # 828905-1
SINGLE-WIRE-SEAL(5MM HOLE)


Customers Also Bought



TE Part #CAR2PC68
CAR PLUG DIN9680 2way, IP68




TE Part #368382-1
MQS RETAINER HSG FOR 81P

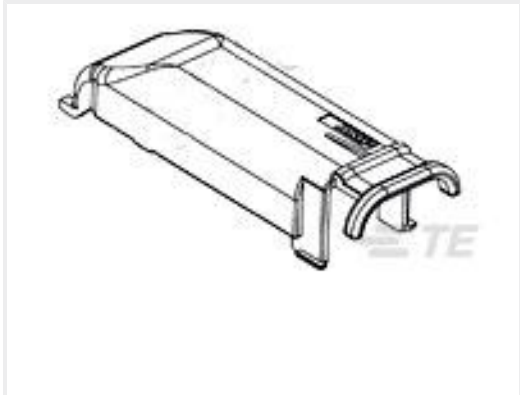


TE Part #368389-1
COVER HSG FOR 81P()




TE Part #368401-1
COVER HSG FOR 40P()

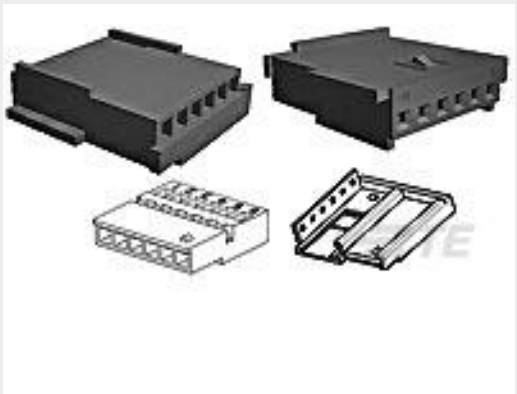


TE Part #1394005-1
6POS MQS REC COD A

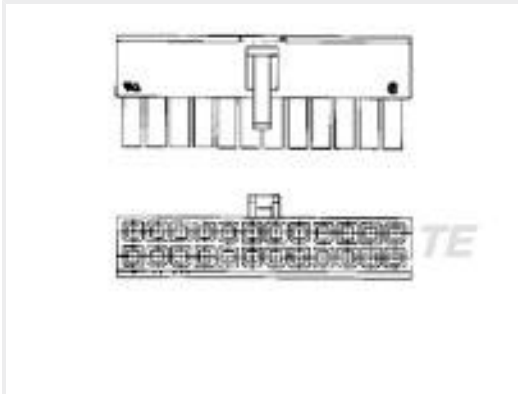


TE Part #1-1586019-8
18P RCPT VAL-U-LOK V0

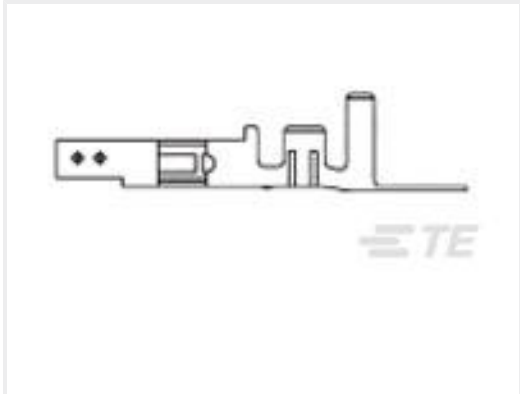


TE Part #1586315-2
VAL-U-LOK SKT BR AU 24-18 LP

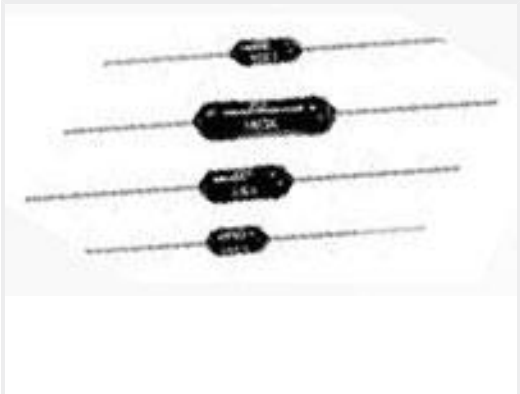

TE Part #8-1879663-5
H8 806R 0.1% 15PPM

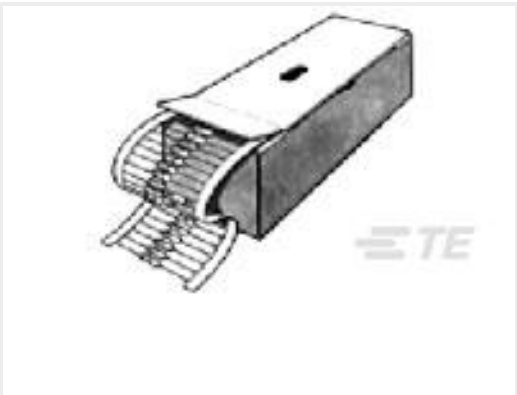

TE Part #1-1879927-2
EP 7W 330R 5%

 

TE Part #3-1355136-7
MQS BU-GEH ASSY 94P

Documents



Product Drawings

81P REC HSG ASSY()BLK-B

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_1-368376-1_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_1-368376-1_G.3d_igs.zip

English

Customer View Model

ENG_CVM_1-368376-1_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English