

**Part Number :** [1300940495](#)


**Product Description :** Bus-Drop Support Grip, Single "U" Eye, Cable Diameter 13.46-18.54mm (.530-.730"), Approximate Break Strength 816.47kg (1800 lbs)

**Series Number :** 130094

**Status :** Active

**Product Category :** Cable Grips

**Engineering Part Number :** 36567

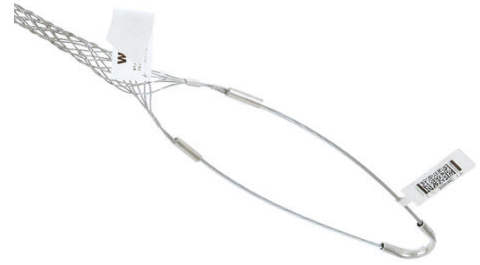

---

## Documents and Resources


### Drawings

[1300940495\\_sd.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

### Part Details

#### General

Status	Active
Category	Cable Grips
Series	130094
Description	Bus-Drop Support Grip, Single "U" Eye, Cable Diameter 13.46-18.54mm (.530-.730"), Approximate Break Strength 816.47kg (1800 lbs)
Product Name	Bus-Drop
Type	Support Grip
UPC	78678836567

#### Agency

CSA	LR32159
UL	E76954

#### Physical

Approximate Break Strength	498.95kg (1100 lbs)
Bale Length	0.229m (9.00")
Body Style	Straight
Cable Diameter	13.46-18.54mm (.530-.730")
Color - Grommet	N/A
Eye Type	Single
Gender	N/A
Material - Body	N/A
Material - Grip	Galvanized Steel
Mesh Length	0.165m (6.50")
Net Weight	40.341/g
Number of Holes	N/A

O-Ring	N/A
Thread Size	N/A

---

This document was generated on Jun 03, 2026