


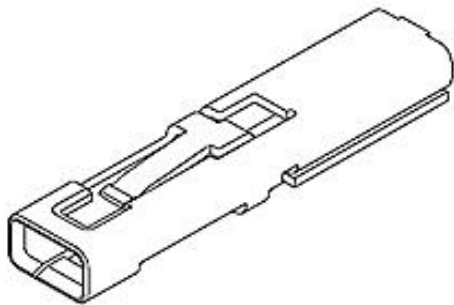

Part Number : [5050720101](#)
Product Description : TermiMate PCB Receptacle
Terminal, 1.20mm Mated Height
Series Number : 505072
Status : Obsolete
Product Category : PCB Headers and Receptacles



Documents & Resources

Drawings

[5050720101_sd.pdf](#)

[5050720101_stp.zip](#)


Specifications

[AS-505071-001-001.pdf](#)

[PS-505071-001-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Compliant with Exemption 33; 44; 34 |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2025)4165-DC (25 June 2025) |
| EU RoHS | Compliant per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|----------------|--|
| Status | Obsolete |
| Category | PCB Headers and Receptacles |
| Series | 505072 |
| Description | TermiMate PCB Receptacle Terminal, 1.20mm Mated Height |
| Application | Board-to-Board |
| Component Type | PCB Receptacle |
| Product Name | TermiMate |
| UPC | 887191571027 |

Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 3.0A |
| Voltage - Maximum | 125V AC (RMS)/DC |

Physical

| | |
|--------------------------------|--------------|
| Circuits (Loaded) | 1 |
| Circuits (maximum) | 1 |
| Durability (mating cycles max) | 10 |
| First Mate / Last Break | No |
| Glow-Wire Capable | No |
| Guide to Mating Part | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Mated Height | 1.20mm |
| Material - Metal | Copper Alloy |
| Material - Plating Mating | Tin |

| | |
|-------------------------------|-----------------------|
| Net Weight | 83.000/mg |
| Number of Rows | 1 |
| Orientation | Right Angle |
| Packaging Type | Embossed Tape on Reel |
| PCB Locator | No |
| PCB Retention | None |
| Pitch - Mating Interface | N/A |
| Plating min - Mating | 0.406µm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | No |
| Temperature Range - Operating | -55° to +105°C |
| Termination Interface Style | Surface Mount |

Mates With / Use With

Mates with Part(s)

| Description | Part Number |
|---|-------------------|
| TermiMate PCB Plug Terminal, 1.20mm Mated Height | <u>5050710101</u> |

Application Tooling

Global

| Description | Part Number |
|---|------------------|
| Unlatching Tool for TermiMate 505071 Plug Terminal for removal of TermiMate 505072 PCB Receptacle Terminal | <u>638245810</u> |

This document was generated on Oct 04, 2025