

CATEGORIES

All

For more information or to request assistance, please contact sales@precidip.com

[« Back to search results](#)

YOUR SELECTED PRODUCT

Screw-machined Contacts

90282

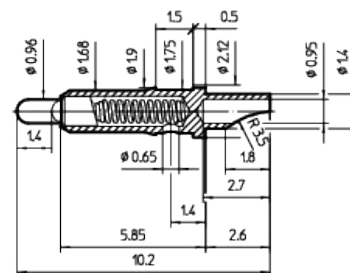
Spring-loaded contacts

For other versions than the listed available standard types, please contact PRECI-DIP

SPECIFICATIONS:

Spring loaded contact for cable wiring

- Solder cup termination
- Press-in mount into dia 1.85 mm hole
- Materials: body + piston brass, spring stainless steel
- Electrical contact resistance max. 30 milliohms
- Mechanical life min. 50'000 cycles

 Metric Inches

AVAILABLE STANDARD TYPES

Ordering Part Number		Height	Stroke	Mid-stroke force
90282-AS	RoHS	10.2 mm	1.4 mm	1.25 N

CAD CATALOG

Literature
Catalog
CAD catalog

ABOUT PRECI-DIP

Career
Contact
Events

OTHER INFO

Feedback
Legal disclaimer
Cross references

NEWSLETTER

Stay informed!

subscription

This website is using cookies for statistics, site optimization and retargeting purposes. You consent to our cookies if you continue to use this website. [Read more here.](#)

powered by
artio

[Accept](#)