




+ CONNECTORS

RACK & PANEL CONNECTORS

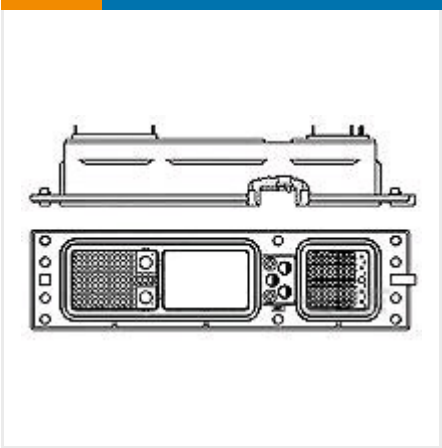

✓ Active

TE CONNECTIVITY (TE)
A600R,Sz2,12072/ / 85 all FR
[AMP](#) | [ARINC 600 Series](#)

2101650-1
TE Internal Number: 2101650-1

Not Yet Reviewed for EU RoHS
Not Yet Reviewed for EU ELV

Connector Style Receptacle
Shell Size 2
Sealable No
Clinch Nuts With

↓ **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings
RCPT ASSY,SIZE 2,ARINC 600 (120T2/DUMMY/85)
PDF (TIFF AVAILABLE)
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.
Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Style Receptacle
Shell Size 2
Sealable No
Product Type Connector

Configuration Features
Keying 130
Release Style Front Release/Remove

Body Features
Shell Plating Material Electroless Nickel

Contact Features
Contact Style Press-Fit
Contact Size 16, 20, 22, 8
Contact Arrangement (Module B) Blank (Dummy)
Contact Arrangement (Module A) 120T2
Contact Type Pin, Socket
Contact Arrangement (Module C) 85

Mechanical Attachment
Hardware Type Flathead Screws
Clinch Nuts With
Clinch Nut Quantity 10
Polarized Yes
Clinch Nut Size 11841

Other
Comment Coaxial contacts must be ordered separately, See drawing for additional product information.

PRODUCT COMPLIANCE

+

Statement of Compliance
Statement of Compliance
PDF