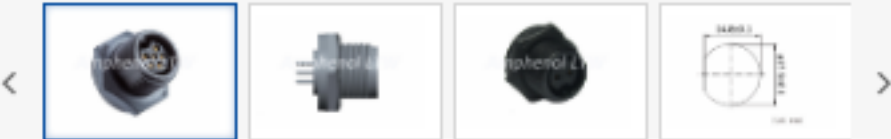


[Products](#)[Customize Your Parts](#)[Industries Solutions](#)[Search](#)[News & Events](#)[First Time?](#)[Home](#) / [Products](#) / [Ceres](#) / [Standard Size](#)

Product Line

[Single Pair Ethernet](#) >[ZConnect](#) >[Ceres](#) >[Accessory](#)[Large Size](#)[Macro Size](#)[Middle Size](#)[Mini Size](#)[Others \(GBD\)](#)[Others \(MAB\)](#)[Others \(PLD\)](#)[Standard Size](#)[X-Lok](#) >[M Series](#) >[FLOS & FLOS+](#) >[Power](#) >[RBL](#) >[HS-Lok](#) >[NM50-0000](#)

ABOUT AMPHENOL LTW

[Heavy Duty Shielded](#) >[RJ](#) >[USB](#) >[SSL](#) >[HDMI](#) >[DVI](#) >[Fiber Optic](#) >[RF](#) >[Cable Joiner](#) >[Cable Gland](#) >[Pressure Relief Vent](#) >[LED Light Guide](#) >[D-Sub](#) >

BD-04PMFP-SC7001

Operating Temperature: -40°C ~ +105°C

Transmission Speed: N/A

Shielded: Plastic, Non-shielded

Jacket Material: N/A

Certificate: UL1977

You must login first for view the price

Quantity

- 1 +

Check Stock

Add to Cart

Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search



Ceres, Standard Size,...
1BD-04AFMM-SI 6A01



Ceres, Standard Size,...
1BD-04AFMM-SI 6A02



Ceres, Standard Size,...
1BD-04AFMM-SI 6A03



Ceres, Standard Size,...
1BD-04AFMM-SI 6A04

ABOUT AMPHENOL LTW

[Heavy Duty Shielded](#) >[RJ](#) >[USB](#) >[SSL](#) >[HDMI](#) >[DVI](#) >[Fiber Optic](#) >[RF](#) >[Cable Joiner](#) >[Cable Gland](#) >[Pressure Relief Vent](#) >[LED Light Guide](#) >[D-Sub](#) >

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

- 0 +



- 0 +



- 0 +



- 0 +



Add to Cart

Inquiry

Specifications

Download / CAD

Nominal Current

5A

Connector Type

Receptacle

Shielded

Plastic, Non-shielded

No. of Contacts

04

Connector Gender

Male

Backshell

Circular

Mating Style

Screw Thread

IP Rating

IPX7

Assembly Style

PCB 180°

More Options

People Also Bought

