


## SmartRack 10U Low-Profile Switch-Depth Wall-Mount Small Rack Enclosure, Clear Acrylic Window, Hinged Back

MODEL NUMBER: SRW10USG

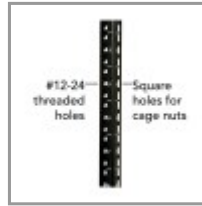

Wall-mount cabinet secures and organizes 10U of 19-inch rack equipment up to 20.5 inches deep in locations with limited floor space. Clear acrylic window allows you to monitor equipment without unlocking door.

### Features

#### Saves Valuable Workspace

- Perfect for network wiring closets, retail locations, classrooms, back offices and other areas with limited floor space where you need equipment to be secure, organized and out of the way
- Houses EIA-standard 19 in. rack equipment in 10U of space
- Maximum load capacity of 200 lb.

#### Hinged Cabinet for Convenient Access

- Swings away from the wall to allow easy back-door access to equipment and cabling during installation and maintenance
- Rotate cabinet 180° before mounting to open reversible doors left or right

#### Shatter-Resistant Clear Acrylic Front Window

- Lets you monitor equipment without unlocking the enclosure
- Prevents equipment tampering
- Reduces acoustic noise
- Provides extra visual flair

#### Keeps Important Equipment Secure

- Side panels and doors lock securely to help prevent damage, tampering or theft
- Vented panels allow generous airflow that keeps equipment cool
- Convenient ports with removable covers allow cable routing through top and bottom

#### Easy Enclosure and Equipment Installation

### Highlights

- Maximum load capacity of 200 lbs (90.7 kgs)
- Swings away from wall on hinge for easy back-door access
- Front door includes shatter-resistant clear acrylic window
- Locking steel cabinet vented at sides, top and bottom
- Secures 10U of 19 in. rack equipment up to 20.5 in. deep

### Package Includes

- SRW10USG SmartRack 10U Low-Profile Switch-Depth Wall-Mount Rack Enclosure Cabinet
- (24) M6 screws
- (24) M6 cage nuts
- (24) M6 washers
- (24) 12-24 screws
- (2) Keys
- Owner's manual



Powering Business Worldwide

TRIPP LITE  
SERIES

- Ships fully assembled for quick installation
- Mounts to wall or rolls on floor with optional SRCASTER caster kit
- Wall-mounting holes spaced 16 in. apart for standard wall stud placement
- Vertical mounting rails adjust in 7/8 in. increments to accommodate equipment up to 20.5 in. deep, such as network switches and patch panels
- Rails support square-hole or 12-24 threaded-hole mounting
- Rack spaces numbered for easy reference

**Meets Payment Card Industry Standards**

- Provides physical equipment and media security required for PCI DSS (Payment Card Industry Data Security Standard) compliance

## Specifications

OVERVIEW	
UPC Code	037332187345
Device Compatibility	Patch Panel; Network Switch; UPS
Rack Type	Small Enclosure
PHYSICAL	
Color	Black
Rack Height	10U
Rack Depth	Shallow
Factory Preset Rack Depth (in.)	10.42
Factory Preset Rack Depth (cm)	26.5
Factory Preset Rack Depth (mm)	265
Maximum Device Depth (cm)	52.07
Maximum Device Depth (in.)	20.5
Maximum Device Depth (mm)	521
Minimum Device Depth (cm)	7.62
Minimum Device Depth (in.)	3
Minimum Device Depth (mm)	76
Shipping Dimensions (hwd / in.)	24.25 x 26.38 x 24.13
Shipping Dimensions (hwd / cm)	61.60 x 67.01 x 61.29
Shipping Weight (lbs.)	59.00
Shipping Weight (kg)	26.76
Unit Dimensions (hwd / in.)	21.560 x 23.630 x 21.630
Unit Dimensions (hwd / cm)	54.77 x 60.02 x 59.94
Unit Weight (lbs.)	53.4



Powering Business Worldwide

TRIPP LITE  
SERIES

Unit Weight (kg)	24.22
Weight Capacity - Stationary (kg)	91
Weight Capacity - Stationary (lbs.)	200
Number of Vertical Mounting Rails	4
<b>FEATURES &amp; SPECIFICATIONS</b>	
Grounding Details	Front and Back door frames
Pre-Installed Casters	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; EIA/ECA-310-E
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.