


EDSTLZ975/X

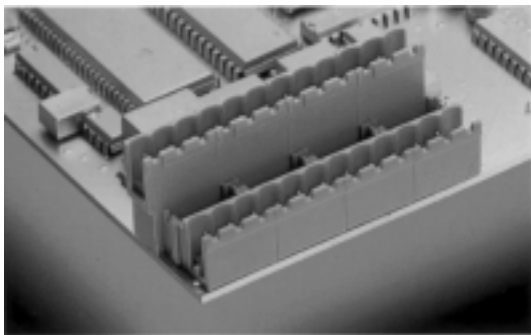

2-12 poles, Spacing 5.08 mm

insert required no. of poles **x**

How to order see page 5



Ratings:

Rated Voltage

300 V

250 V

Rated Current

15 A

12 A (T60)

Rating Impulse Voltage/Dirt Level

4 kV/3

Dimensions

Spacing

5.08 mm

PCB Hole Diameter

1.4 mm

Materials

Insulating Material

PA/PBTP

Flammability Class

UL94 V-0

Temperature Range

-30°C/+105°C

Contact Pin

Cu

Color

Green

