


OD9225 Sealed Sleeve Series



DC Fans - 12, 24V
92mm x 25.4mm (3.6" x 1.0")

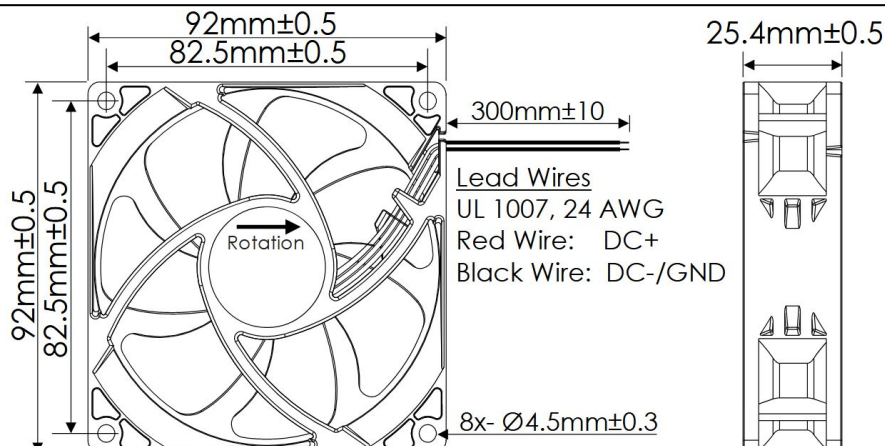

Frame	PBT, UL94 V-0 Plastic	<u>Operating Temperature</u> -20°C ~ +65°C	Static Pressure ("H₂O") Airflow (CFM)
Impeller	PBT, UL94 V-0 Plastic	<u>Storage Temperature</u> -20°C ~ +75°C	
Connection	2x Lead Wires, 24 AWG	<u>Life Expectancy</u> 50,000 Hours (L10 at 40°C)	
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected, Electronically Protected	<u>Available Options</u> PWM Speed Control Input Tachometer Output Alarm Output Other Speeds IP Ratings	
Bearing System	Sealed Sleeve Bearings	Weight: 0.18 lbs	
Dielectric Strength	500VDC/min, <1mA		
Insulation Resistance	≥10M Ohm @ 500 VDC		

Part Number	Rated Voltage (Volts DC)	Voltage Range (Volts DC)	Input Power (Watts)	Rated Current (Amps)(Max)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O")
OD9225-12HSS	12	8 ~ 13.8	3.5	0.29	3275	60.2	38	0.25"
OD9225-24HSS	24	15 ~ 26.4	4.3	0.18	3275	60.2	38	0.25"