


Foot Candle/Lux Meter

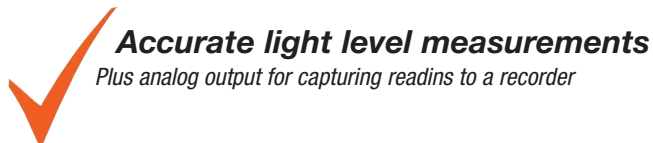

Accurate light level measurements

Plus analog output for capturing readings to a recorder

Features:

- Accurately displays light level in terms of Fc or Lux over three ranges:
Fc (0-200, 0-2000 and 0-5000Fc) and
Lux (0-2000, 0-20000, 0-50000Lux)
- Resolution of 0.1Fc or 1Lux
with 5% accuracy
- Select fast (0.2 second) or slow
(0.4 seconds) response
- Monitor light levels using outputs;
1mV per count analog output for
capturing readings to a recorder
- Utilizes precision photo diode and color
correction filter; Cosine/color corrected
- Dimensions: 6.4 x 2.8 x 1.2" (163 x 70 x 30mm);
Weight: 7.8oz (220g)
- Complete with 9V battery and light sensor with 45" (1.1m)
cable and protective cover



Ordering Information:

401025.....Foot Candle/Lux Meter
401025-NIST401025 with NIST Certificate
409996.....Vinyl Pouch Carrying Case

