


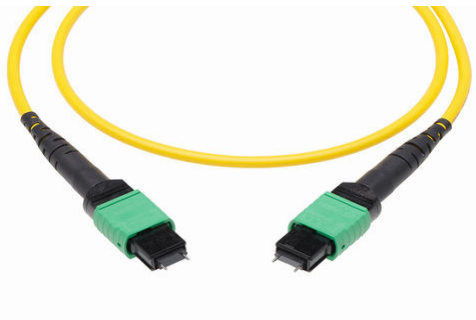

Part Number : [1062830205](#)
Product Description : QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable
Series Number : 86004
Status : Active
Product Category : Fiber Optic Cable Assemblies



Documents and Resources

Drawings

[1062830205_sd.pdf](#)

Specifications

[1062840501-000.pdf](#)

[1062830201-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	86004
Description	QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable
Connector to Connector	MPO/APC-to-MPO/APC
Keyword	16F
Mode	Singlemode
Product Name	MPO,QSFP-DD Optical Cables
UPC	195842046382

Agency

CSA	LR64395
UL	E72548

Physical

Boot Type	Straight
Cable Length	5.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	9/125µm
Net Weight	1.000/g
Single Ended	No
Wire/Cable Type	16 Fiber Bend-insensitive Plenum

This document was generated on May 27, 2026