
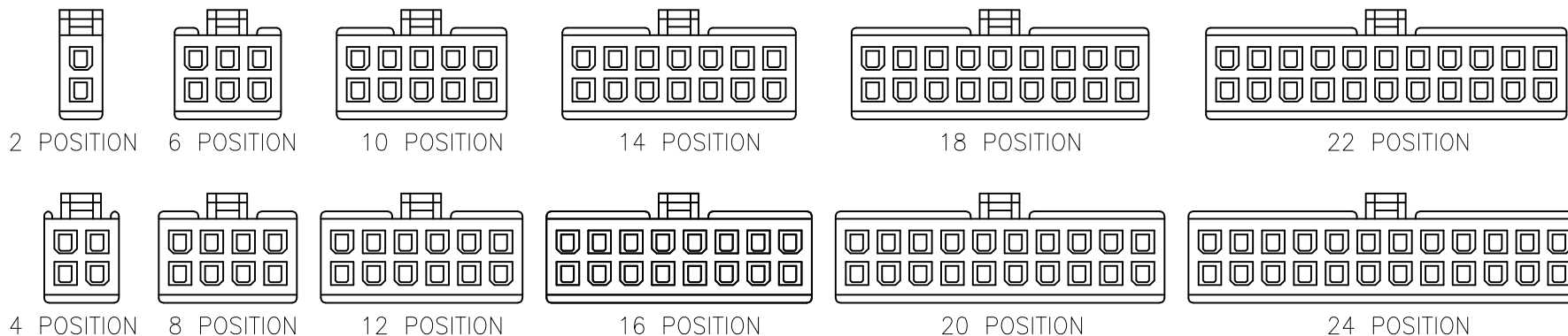
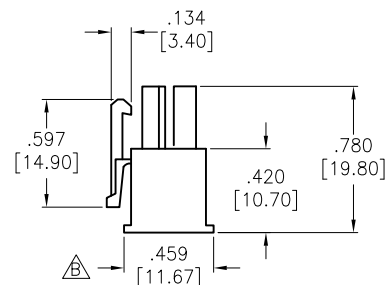
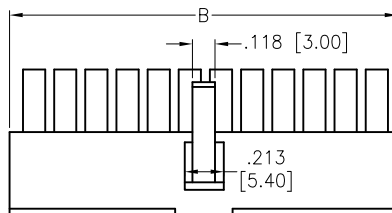


APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	6/21/18	
A		UPDATE SPEC.	6/18/19	AY/KC
B		ADDED DIM.	10/21/20	AY/NP

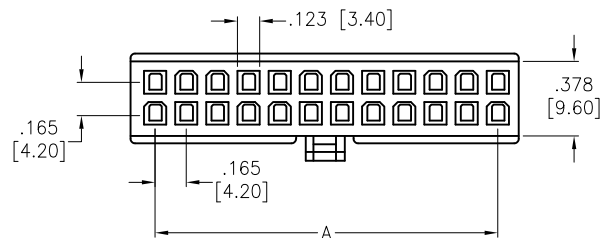

Positions: 2, 4, 6, 8, 10, 12, 14, 16, 18, 20, 22, 24
A = .165 [4.20] X No. of Spaces per row
B = .165 [4.20] X No. of Positions per row + .055 [1.40]

SPECIFICATIONS:

Material:

Insulator: Nylon 66, rated UL 94V-2, Glow Wire Compliant

Insulator color: Natural

Electrical:

Operating voltage: 600 VAC max

Current rating: / Circuit (See Chart)

Insulation resistance: 1000 Mohms min @ 500 VDC

Dielectric withstanding voltage: 1500 VAC for 1 minute

Temperature Rating:

Operating temperature: -40° to +105°

Environmental:

Lead free, RoHS compliant.

WIRE SIZE	CIRCUITS			
AWG	2	4~6	8~10	12~24
18	9 A	8 A	7 A	6 A
20	7 A	6 A	5 A	5 A
22	5 A	4 A	4 A	4 A
24	4 A	3 A	3 A	3 A



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE INCHES [MM]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES

.X ±.10 Ø.X ±.10
.XX ±.020 Ø.XX ±.015
.XXX ±.015 Ø.XXX ±.010

APPROVALS		DATE
DRAWN	SS	8/18/06
CHECKED		
APPROVED		

**ADAM
TECH**

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
WIRE TO WIRE CONNECTOR HOUSING
FEMALE, 4.2MM PITCH, GLOW WIRE

SIZE	PART NO.	REV.
X	DMH-XX-GW	B
REF:	S00123T	SCALE: NTS
SHEET 1 OF 1		