

Quick Links

Cross reference

RoHS/LF P/N Search

Industry Standards

Alphabetical List

Documentation

3D model search

Customer drawing search


Multi Selection Search

Search by category

Start > Search=10125559-102LF* > 10125559-102LF

10125559-102LF

10125559-102LF - AIRMAX VS2®: 4-Pair, 120 -position, 2 mm pitch, 10 column, Vertical Receptacle

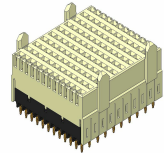

Customer drawing

Product Environmental Compliance Report

Specifications

Download document

ACTIVE

RoHS Compliant

Distributor Stock

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

Dimensional General Physical	
Dimensional	
Pitch (Slot - min)	20 mm
Stack Height	12.5 mm
Spacing (Column)	2 mm
General	
Number of contacts	120
Orientation	Vertical
Product Series	AirMax VS2
Style	Signal Receptacle 2 mm
Termination Style	Standard Press-Fit
Number of columns	10
Number of differential pairs (per column)	4
Physical	
Material (Contact)	Copper Alloy
Material (Housing)	Hi-Temp Thermo Plastic
Plating (Contact)	Au over Ni

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.