

AMMA00131364R15MV1

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




NEW ?

Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

Series Pdf

Product detail		
L(mm) ±		12.9Max.
W(mm) ±		13.2±0.5
T(mm) ±		6.4Max.
Inductance(uH)		0.15
Tolerance(±%)		20
Test Frequency		100kHz,0.25V
RDC(Ω)Max		0.0006
RDC(Ω)Typ		0.00053
Isat(A)Typ		118
Irms(A)Typ		55
Operating Temperature		−55℃~125℃

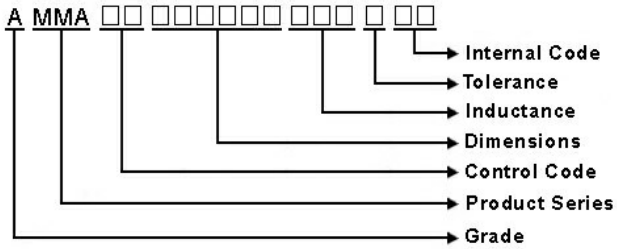

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Filter/Antennas
- RF-Wireless Power Transfer
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



[Inductor](#)



[Resistor](#)



[Powder](#)

Copyrights © 2018. Chilisin. All rights reserved.