

# Mallory Sonalert Products, Inc.

Part #:

**SC110ER**

## Sales Outline Drawing

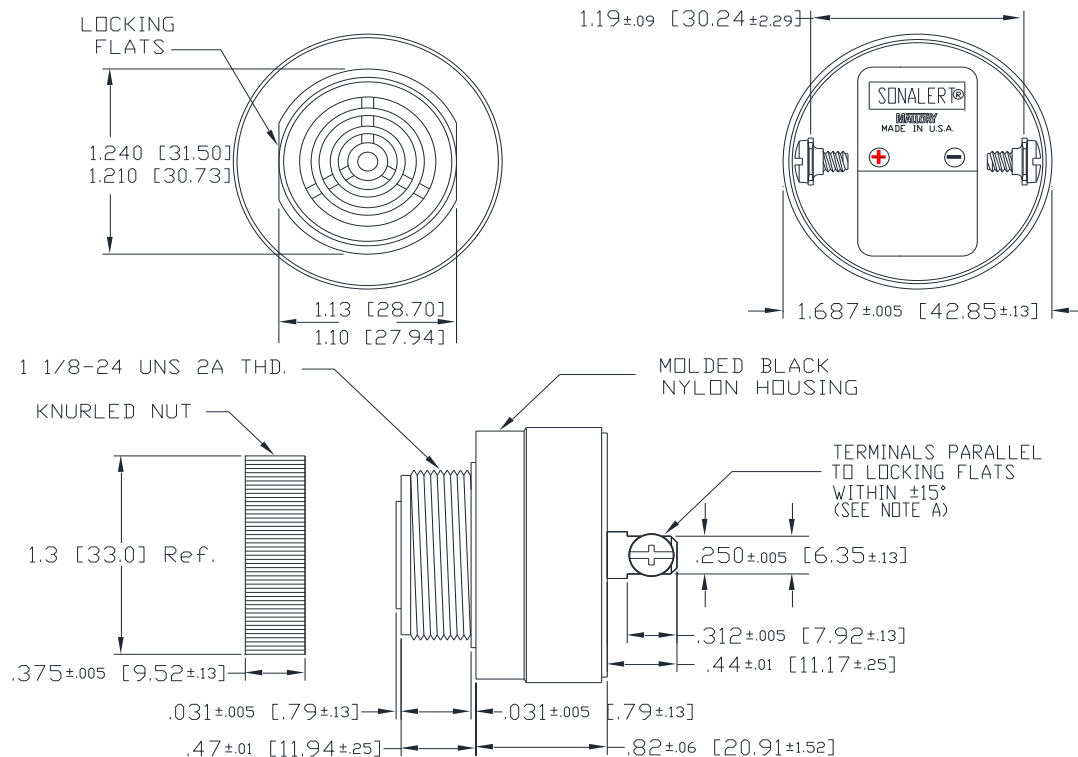
Revision:

**F**

### Specifications:

|                       |                                                                                            |
|-----------------------|--------------------------------------------------------------------------------------------|
| Sound Level Category  | Soft                                                                                       |
| Mode of Operation     | Continuous                                                                                 |
| Voltage Rating        | 30 to 120 VAC/DC                                                                           |
| Frequency             | 2000 $\pm$ 500 Hz                                                                          |
| Loudness @ 2 FT       | 54 to 67 dB(A) Typ.                                                                        |
| Loudness @ Min Vdc    | 50/63 dB(A) @ 2 Feet and 30 Vdc                                                            |
| Loudness @ Max Vdc    | 65/78 dB(A) @ 2 Feet and 120 Vdc                                                           |
| Current Draw          | 4-10mA                                                                                     |
| Housing Material      | 6/6 Nylon, Color: Black                                                                    |
| Storage Temperature   | -40° to +85° C                                                                             |
| Operating Temperature | -30° to +65° C                                                                             |
| Panel Mounting        | Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole. |
| Knurled Nut           | Used to attach part to panel. The max recommended torque is 10 in-lbs.                     |
| Weight (Typical)      | 1.6 oz (45g)                                                                               |
| NEMA 3R,4X, & 12      | Approved with use of ACC03.                                                                |
| Options               | Please contact factory.                                                                    |

### Dimensions: Inches (mm)

**ROHS Compliant**

NOTE A: TERMINALS-.032 BRASS TIN PLATED, TAPPED FOR #6-32 SCREW. TWO #6-32 NICKEL PLATED BRASS SCREWS INCLUDED. WILL ACCEPT 1/4" QUICK CONNECT.

NOTE B: MOUNTING- REMOVE BLACK PLASTIC NUT AND INSERT THREADED FRONT THROUGH 1.25" HOLE PUNCHED IN PANEL, IF ORIENTATION IS NEEDED, NOTE LOCKING FLATS ON DRAWING. SCREW NUT BACK ON. DO NOT OVERTIGHTEN.