
 



TOP VIEW

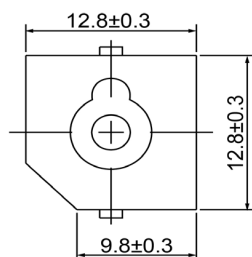


SIDE VIEW (1)



 
SIDE VIEW (2)



BOTTOM VIEW

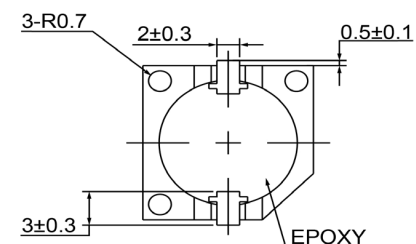

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Technology	Electro-Mechanical		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	2,300	(Hz)							
Rated Voltage	5	(V)							
SPL @ 10cm	85	(dBA)							
Tone	Single								
Mount Type	Surface Mount								
Voltage Range	3 ~ 7	(V)							
Max Rated Current	30	(mA)							
Housing Material	PPS								
Operating Temperature	-30 ~ +70	°C							
Storage Temperature	-40 ~ +85	°C							
Weight	2	(g)							
			 DB UNLIMITED	Electro-Mechanical Indicator			IE122305-6		

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.