

Standard



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[BKT series](#)

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 4.50 - 5.20 mm   |
| Size                               | 0B               |
| Series                             | B - Indoor keyed |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-0b-045-dn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-045-dn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Form & Material

|                        |                            |
|------------------------|----------------------------|
| Shell style / Model id | GMA - Bend relief Black    |
| Housing material       | Thermoplastic polyurethane |
| Keying                 | No keying                  |
| Colour                 | Black                      |
| Weight                 | 0.42 g                     |


## Environment

|                                   |  |
|-----------------------------------|--|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating   |
| Temperature range                 | -40°C / +80°C  |

## Cable fixation

|                                    |                |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 4.50 - 5.20 mm |
|------------------------------------|----------------|

## Drawings

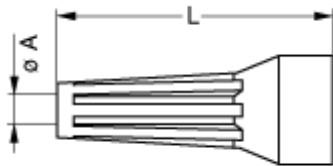

No keying

## Dimensions

|     | A    | L    |
|-----|------|------|
| mm. | 4.5  | 24   |
| in. | 0.18 | 0.94 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-0b-045-dn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-045-dn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.