



Color: ■ gray

Similar to illustration

Electrical data

Ratings per IEC/EN

Rated current	16 A
---------------	------

Physical data

Width	10 mm / 0.394 inches
Height	10 mm / 0.394 inches
Depth	4 mm / 0.157 inches
Jumper assignment	1-2

Material data

Note (material data)

[Information on material specifications can be found here](#)

Color	gray
Material group	I
Insulation material	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.008 MJ
Weight	0.6 g

Environmental requirements

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C



Commercial data	
Product Group	9 (Std Chassis Mt Blocks)
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 8.0	EC000489
ETIM 7.0	EC000489
PU (SPU)	500 (25) pcs
Packaging type	Box
Country of origin	PL
GTIN	4045454033736
Customs tariff number	85366990990

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 261-402	↓

Documentation				
Additional Information		Bid Text		
Technical Section	pdf 2246.92 KB	261-402	19.02.2019	xml 2.62 KB
	↓	261-402	17.08.2017	doc 23.50 KB
				↓

CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 261-402	EPLAN Data Portal 261-402
↓	↓
	WSCAD Universe 261-402
	↓
	ZUKEN Portal 261-402
	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Tool

1.1.1.1 Operating tool




Item No.: 209-132

Operating tool; for connecting comb-style jumper bar; made of insulating material; 2-way; natural

Installation Notes

Commoning

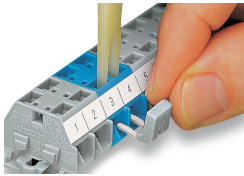

Commoning with comb-style jumper bar.