




By Burndy
Catalog # [1PBS1/O](#)

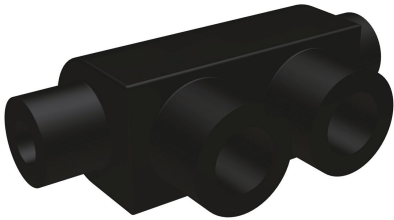

UV Rated Black UNITAP™ Splice/Reducer

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application

For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - UL Listed Direct Burial	No

Conductor

Conductor - Copper Str Size Range	14 AWG - 1/0 AWG
Conductor Type	AL C Str-Size;CU C Str-Size
Conductor - AL Str Size	14 AWG;12 AWG;10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0
Conductor - AL Str Size Range	14 AWG - 1/0 AWG

Configuration

Physical Attribute - Number of Screws	2
Number Of Ports	2

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Width inch	0.91 in
Dimension - Width mm	23 mm
Dimension - Height fraction	1.375 in
Dimension - Height inch	1.38 in
Dimension - Height mm	35.1 mm
Dimension - Screw Size inch	7/16
Dimension - Width fraction	91/100 in

Force Related

Installation Torque	120 in-lb
Recommended in-lb	

General

Sub Brand	UNITAP
Material - Hardware	Aluminum
Insulation Type	Plastisol
Trade Name	UNITAP™
Type	BIBS, Multi-Port
UPC 12 Digit	781810295922
UPC 14 Digit GTIN	00781810295922
Material	Aluminum
Hex Key	3/16
UPC	781810295922

Logistics

Carton Quantity	100
-----------------	-----

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)