

SySTIUM®


 

Power Adapters

LONG LIFE

CERTIFIED



SySTIUM® Technologies Power Adapters are made for embedded applications requiring long life and certifications. We understand how frustrating it can be finding a solid source for power adapter. SySTIUM can be your trusted source for 12V and 19V applications.

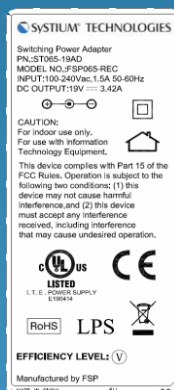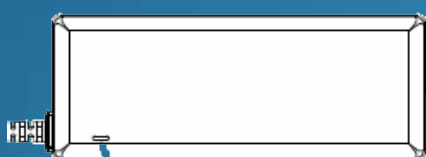

Features:

- Full Range AC Input
- Meets Energy Star EPS 2.0/ ErP Lot 7
- With PFC Circuit
- C8 AC input, US Power cord incl.

Specifications:

- Input Freq. 47-63Hz
- Over Current Protection
- Over Temperature Protection
- Over Voltage Protection
- Operating Temperature: 0 ~ +40C
- Storage Temperature: -30 ~ +60C

Certifications:

- EMC- EN55022 Class B
- EMC EN55024 Class B
- Safety CB, TUV, UL/cUL, FCC, CE
- MTBF: 100K hrs @ 25C

	12V	19V	
Model	<u>10611-60</u>	<u>10619-65</u>	<u>10619-90</u>
Wattage	60W	65W	90W
AC Socket	C13	C8	C8
Power Cord	US, Included	US, Included	US, Included
Tip	Barrel 90°, 2.5x5.5x11	Barrel 90°, 5.1x7.4x??	Barrel 90°, 5.1x7.4x??
Board Compatibility	Intel® D2800MT	Intel® DQ77KB, Intel® NUC	Intel® DQ77KB, Intel® NUC
Optional Tip	NA	Barrel 90°, 2.5x5.5x11	Barrel 90°, 2.5x5.5x11