


Product data sheet

Specifications

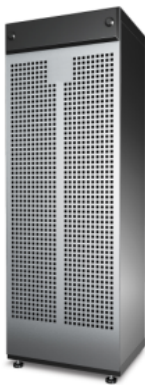

MGE Galaxy 3500 Extended Run Enclosure, with MCCB, with 6 Battery Modules

G35TBXR6B6

⚠ Discontinued on: 05 July 2021

⚠ To be end-of-service on: 31 December 2030

⚠ Discontinued - Service only

Overview

Lead time Usually Ships within 2 Weeks

Main

Main Input Voltage 208 V 3 phases
400 V 3 phases

Battery type Lead-acid battery

Provided equipment Installation guide

Physical

Colour Grey

Height 149.9 cm

Width 52.3 cm

Depth 92.5 cm

Net weight 776 kg

Mounting mode Not rack-mountable

Input

Network frequency 50/60 Hz

Conformance

Product certifications CSA

Standards CSA C22.2 No 107.1

Environmental

Ambient air temperature for operation -5...45 °C

Operating altitude 0...10000 ft

Relative humidity 0...85 %

Ambient air temperature for storage 0...30 °C

Storage altitude 0.00...4572.00 m

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Storage Relative Humidity	0...85 %
---------------------------	----------

Batteries & Runtime

Battery location	Battery cabinet
Number of battery blocks per string	4
Number of battery free slots	0
Number of battery filled slots	6
Device mounting	Enclosed battery cabinet

Packing Units

Unit Type of Package 1	Db
Number of Units in Package 1	1
Package 1 Height	164.3 cm
Package 1 Width	106.2 cm
Package 1 Length	65 cm
Package 1 Weight	807 kg

Offer Sustainability

EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Contractual warranty

Warranty	1 year repair or replace
----------	--------------------------

Recommended replacement(s)