



0

[Heatsinks](#) » [Profile heatsinks and fluid coolers](#) » [Standard extruded heatsinks](#) » [SK 109 ...](#) » [SK 109](#) » **[SK 109 200 SA](#)**

Standard extruded heatsinks

SK 109 ...

SK 109 200 SA

125 x 135 mm, with guide away for cover plates or blanks

surface:

black anodised

length:

200 mm

 
Quantity



1



Add to inquiry



Overview

Features

Variants

Technical Drawing


Service

Data sheet

Features

thermal resistance:	0.8 - 0.35 K/W
surface:	black anodised
height:	135 mm
width:	125 mm
length:	200 mm
plate thickness:	14 mm

Variants

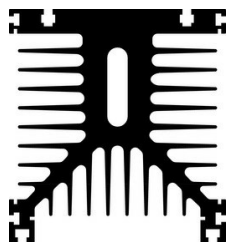

SK 109 200 SA

- surface: black anodised
- length: 200 mm

Thermally conductive material	Certification	Exhibitions and Conventions	Sample	Itinerary
Cases f.case - product search	Contract Terms and Conditions ...		Downloads	
Connectors f.con - product search	General sales conditions		Technical informations	
	General Terms and Conditions ...		Links	
			Sampling	



ISO 9001
ISO 14001
ISO 27001

[Feedback](#)[Sitemap](#)[Data Protection](#)[Site notice](#)

In order to optimize our website for you and to be able to continuously improve it, we use cookies. By continuing to use the website, you agree to the use of cookies.

[More Info](#)

[Agreed](#)