


# ED700/X (5.0 mm) EDZ700/X (5.08 mm)

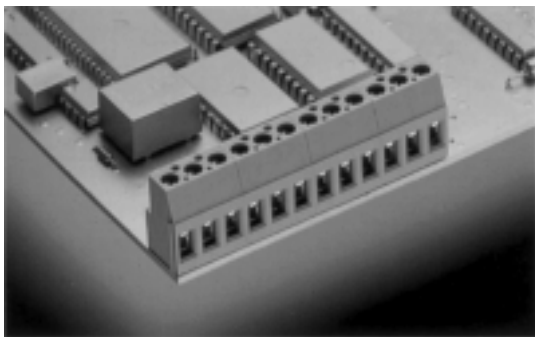

2-12 poles, Spacing 5.0 mm and 5.08 mm  
insert required no. of poles **X**  
How to order see page 5



## Ratings:

|                        |           |                     |
|------------------------|-----------|---------------------|
| Rated Voltage          | 300V      | 250 V               |
| Rated Current          | 20 A      | 24 A (T60)          |
| Wire Size              | AWG 30-12 | 2.5 mm <sup>2</sup> |
| Test Voltage           |           | 2.0 kV              |
| Rated Torque/ScrewSize |           | 0.5 Nm/M3           |

## Max. Rated Cross Section

|                             |                     |
|-----------------------------|---------------------|
| Single Wire (solid)         | 4.0 mm <sup>2</sup> |
| Stranded Wire (flexible)    | 2.5 mm <sup>2</sup> |
| Stranded wire with Ferrules | 2.5 mm <sup>2</sup> |

## Dimensions

|                   |                  |
|-------------------|------------------|
| Spacing           | 5.0 mm (5.08 mm) |
| PCB Hole Diameter | 1.3 mm           |
| Stripped Length   | 8.0 mm           |

## Materials

|                     |              |
|---------------------|--------------|
| Insulating Material | PA           |
| Flammability Class  | UL94 V-0     |
| Temperature Range   | -30°C/+105°C |
| Terminal Block      | CuZn         |
| Wire Guard          | Cu           |

## Color

Green

