

Han hinged frame plus, for 4 modules a-d

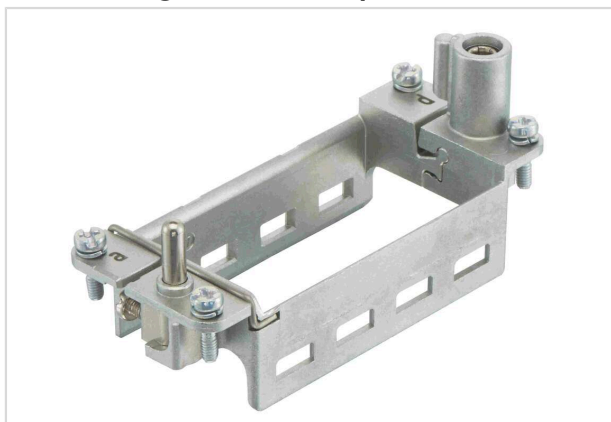


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 016 0371
Specification	Han hinged frame plus, for 4 modules a-d
HARTING eCatalogue	https://harting.com/09140160371

Identification

Category	Accessories
Series	Han-Modular®
Type of accessory	Hinged frame plus
Description of the accessory	for 4 modules a ... d

Version

Size	16 B
------	------

Technical characteristics

Conductor cross-section	1 ... 10 mm ² PE (power side)
	0.5 ... 2.5 mm ² PE (signal side)
	The use of ferrules is recommended, conductor cross-section 10 mm ² only with ferrule crimping tool 09 99 000 0374.
Stripping length	8 ... 10 mm
Tightening torque	0.8 Nm PE screw M3
	1.2 Nm PE screw M4
Recommended screw driver	Slotted 0.6 x 3.5 PH2
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

Material properties

Material	Zinc die-cast Stainless steel
RoHS	compliant



Pushing Performance
Since 1945

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	IEC 60664-1
	IEC 61984
	IEC 61373 Category 2
UL / CSA	UL 1977 ECBT2.E235076
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	4.67 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140161979
eCl@ss	27440206 Module carrier frame for industrial connectors
ETIM	EC002312
UNSPSC 24.0	39121421